

Universal socket strip 3-fold IEC 320

Item-No.: 0200x02032308 (1,5 m cord)



Robust plastic, grey

Built-in sockets (90° rotated), round

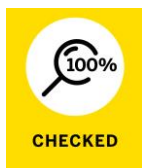
Extra large space in between sockets 64 mm

1,5 m power cord with IEC connector (IEC 320)

Expanded contact protection by using a shutter




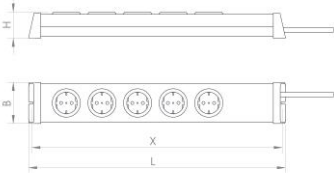
Integrated circuit breaker 10A

End caps with mounting possibility



Universal socket strip 3-fold IEC320

Technical data

2.500 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	10 A Rated current
Power Cord: H05VV-F 3G 1,5 mm ² Plug: IEC connector (IEC 320) Sockets: type E (French Standard) Circuit breaker: 10A Safety class: IP20		  
 <p>(similar illustration)</p>		
Item-No. 0200x02032308 (1,5 m cord) EAN 401209600479 0 PU 10		270 x 74 x 47 mm Dimensions (L x W x H) 262 mm Fixing Dimension