
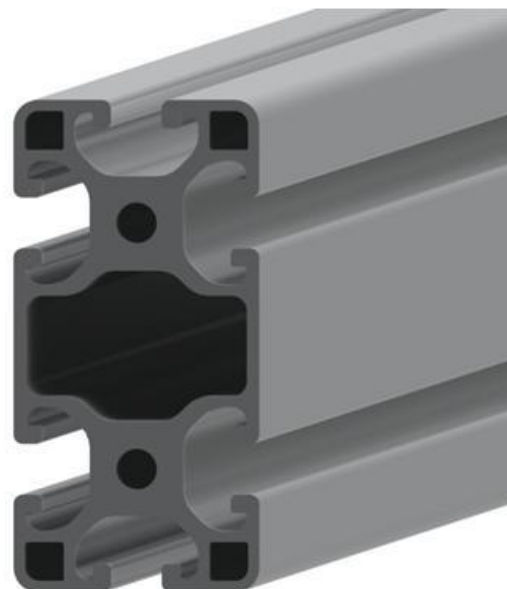


Datasheet

## Profile 8 80x40 light

RS Article no.: 7613325 & 7613329

ENGLISH

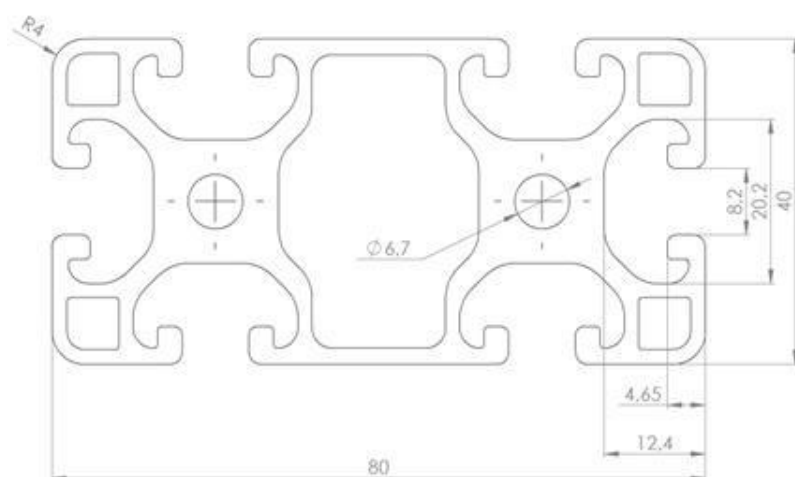

<b>Profile:</b>	<b>80mm x 40mm</b>
<b>Groove size:</b>	<b>8mm</b>
<b>Profile Length:</b>	<b>2000mm &amp; 3000mm</b>
<b>No. of grooves:</b>	<b>6</b>
<b>Material:</b>	<b>Anodized Aluminium</b>

Moment of inertia	$I_x$	70.16 cm <sup>4</sup>
Section modulus	$W_x$	17.54 cm <sup>3</sup>
Mass	G	3.06 kg/m
Profile groove		8 mm
Packing Unit	PU	8 pcs.

### Technical data strut profiles

EN AW - 6063	DIN EN 573
Anodizing	E6EV1



RS Article no.	40 Character Description	Profile Length
7613325	Profile 8 80x40 light 2m	2000mm
7613329	Profile 8 80x40 light 3m	3000mm