

ORIGINAL - METAL BASE T4W

Original spare part



The cost-effective original spare parts for trucks

Discover OSRAM's ORIGINAL signal lamps with metal bases - high-quality original spare parts for 24 volt lamps. Due to the wide product range, the lamps can be used for different applications: as position and parking lights, indicator, brake, fog and reversing lights as well as number plate and side position lights.

Technical data

Product information

Order reference	3930
Application (Category and Product specific)	Auxiliary lamp


Electrical data

Power input	5 W
Nominal voltage	24.0 V
Nominal wattage	4.00 W
Power input tolerance	±10 %
Test voltage	28.0 V

Photometrical data

Luminous flux	35 lm
Luminous flux tolerance	±20 %

Dimensions & weight

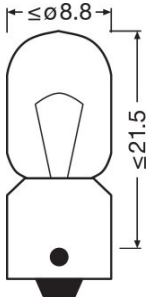

Length	27.4 mm
Diameter	8.8 mm
Product weight	2.02 g

Lifespan

Lifespan B3	550 h
Lifespan Tc	1000 h

Additional product data

Base (standard designation)	BA9s
-----------------------------	------

Product datasheet

Capabilities

Technology	AUX
------------	-----

Certificates & standards

ECE category	T4W
--------------	-----

Country specific categorizations

Order reference	3930
-----------------	------

Environmental information

Date of Declaration	29-12-2021
Primary Article Identifier	4050300926001 4050300838366 4050300880273
Candidate List Substance 1	No declarable substances contained
CAS No. of substance 1	No CAS
Safe Use Instruction	The identification of the Candidate List substance is sufficient to allow safe use of the article.
Declaration No. in SCIP database	No declarable substances contained

Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4050300838366	OSRA3930	-	4739924	-
4050300525143	OSRA3930	-	4739924	-
4050300838366	OSRA3930	-	4739924	-

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300838366	ORIGINAL - METAL BASE T4W	Unpacked 1	- x - x -		
4050300525143	ORIGINAL - METAL BASE T4W	Folding carton box 10	46 mm x 29 mm x 112 mm	0.15 dm ³	31.10 g
4008321095695	ORIGINAL - METAL BASE T4W	Shipping carton box 50	148 mm x 115 mm x 55 mm	0.94 dm ³	185.00 g
4050300926001	ORIGINAL - METAL BASE T4W	Blister 2	95 mm x 70 mm x 18 mm	0.12 dm ³	9.00 g
4008321140302	ORIGINAL - METAL BASE T4W	Shipping carton box 20	137 mm x 105 mm x 81 mm	1.17 dm ³	128.50 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Product datasheet

Application advice

For more detailed application information and graphics please see product datasheet.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.



OSRAM