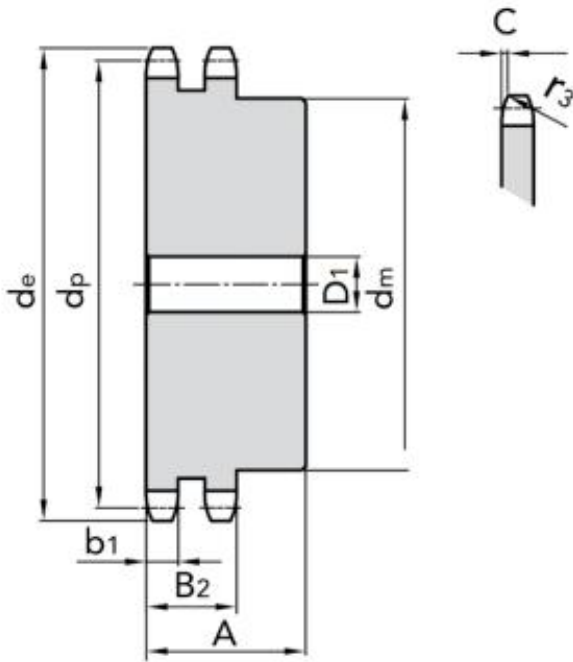


10219013

3/4in x 7/16in - Chain sprockets ISO

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Number of teeth (T)	13
de (DE) mm	87.13
dp (DP) mm	79.60
Part number (CODE)	10219013
dm (DM) mm	59
D1 (D1) mm	16
A (A) mm	50
Tooth radius r3 (R3) mm	19
Radius width C (C) mm	2
Sprockets tooth width b1 (B1) mm	10.8
Sprockets tooth width B2 (B2) mm	30.3
Weight (WEIGHT) kg	1.25
Material (MAT)	STEEL C 45