

A.VE - PROTWIST® 1,000 VOLT INSULATED SCREWDRIVERS FOR SLOTTED-HEAD SCREWS | A4X100VE




Norm :

NF ISO 2380-1, NF ISO 2380-2, NF EN 60900, ISO 2380-1, ISO 2380-2, EN 60900, DIN ISO 2380-1, DIN ISO 2380-2, DIN EN 60900, ASME B107.600

Description

- For your safety, each screwdriver is tested individually at 10,000 Volt for 10 seconds, at the end of the manufacturing cycle.
- 1,000 Volt sheathed round blade.
- Milled blade: --> 5.5 mm included.
- Fillet blade: 6.5 --> 12 mm.
- Bi-material grip resists to impacts, abrasion, and chemicals.

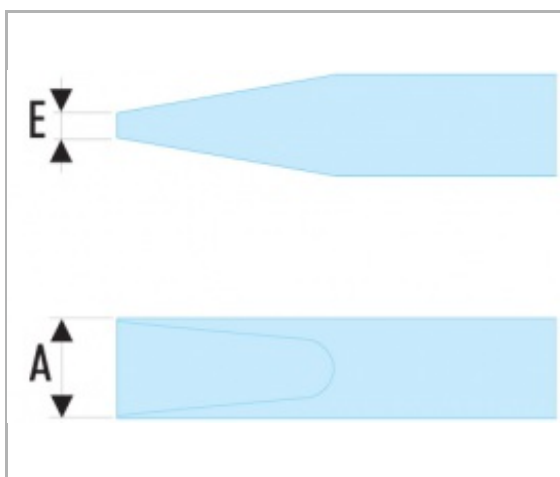

Information

A [mm]	4,0
d [mm]	30
E [mm]	0,8
L [mm]	210
L1 [mm]	100
L2 [mm]	110
[g]	48