

**Perfo Panel Racks & Trolleys**

Freestanding or mobile panel racks utilising our proven perfo or louvre systems. Designed to provide high capacity storage especially suitable for hand tools. Position at the point of use to increase productivity.

These new models have been developed to offer the same renowned bott performance at a reduced cost price.

- 3 static heights, 1125mm, 1450mm and 1775mm
- 1250mm high mobile has 100mm diameter castors
- All models 1000mm wide x 550mm deep
- Double or single sided versions
- Empty for custom layouts or complete with hook kits
- Epoxy powdercoat finish
- RAL7035 light grey frames with RAL5010 blue panels
- Optional base tray available for all double sided models

**Optional Base Tray**  
(suitable for double sided models)



Item	Order Ref.	Price £
Drop in base tray	16917030.51V	18.84

**1250mm High Mobile Rack**



Type	Hook Kit	Order Ref.	Price £
Double	/	16917160.11V	251.18
Double	40 piece	16917260.11V	313.98

**1125mm High Static Rack**




Type	Hook Kit	Order Ref.	Price £
Single	/	16917105.11V	167.46
Single	20	16917300.11V	204.68
Double	/	16917100.11V	219.79
Double	40 piece	16917200.11V	282.58

**1450mm High Static Rack**



Type	Hook Kit	Order Ref.	Price £
Single	/	16917106.11V	188.39
Single	30	16917301.11V	217.19
Double	/	16917101.11V	251.18
Double	60 piece	16917201.11V	334.91

**1775mm High Static Rack**

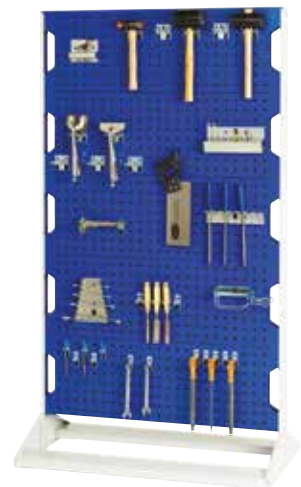

Type	Hook Kit	Order Ref.	Price £
Single	/	16917107.11V	209.32
Single	40	16917302.11V	272.35
Double	/	16917102.11V	282.58
Double	80 piece	16917202.11V	387.24