




FAG

SES506-605-L [↗](#)

Plummer block housing




Split plummer block housing for various bearing designs. The SNV series will be replaced by the new SES series in 2022.

Technical information

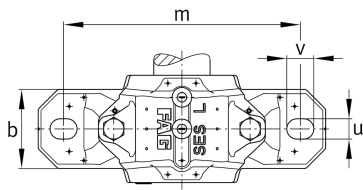

Main Dimensions & Performance Data

D	62 mm	Outside diameter bearing
a	185 mm	Length base
h ₁	89 mm	Height
g	77 mm	Width housing body
K	32 mm	Width bearing seat
≈m	2.13 kg	Weight

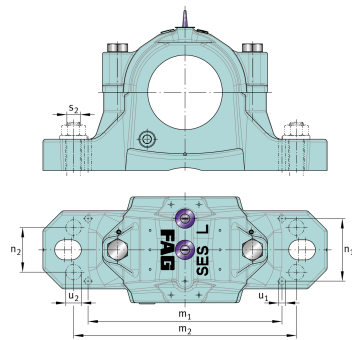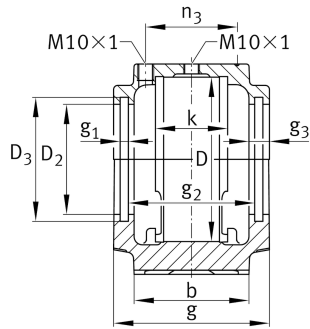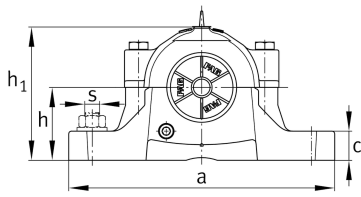

Dimensions

b	52 mm	Width base
c	22 mm	Height base
h	50 mm	Base to shaft centerline height
m	150 mm	Distance fixing bore
s	12.7 mm	Screw size
s	M12	Size of fixing screws
u	15 mm	Width slot
v	20 mm	Length slot
D 2	36.5 mm	Diameter sealing
D 3	44.5 mm	Diameter sealing groove
D 5	42.7 mm	Outside diameter sealing labyrinth
g 1	5 mm	Width sealing groove
g 2	62 mm	Distance sealing
g 3	10 mm	Wall thickness
g 4	23 mm	Distance oil lubrication
m 1	119 mm	Distance holes aligned pins m1
n 3	42 mm	Distance lubrication
n 4	63 mm	Distance lubrication sealing
u 1	4 mm	Bore diameter u1
u 2	9 mm	Bore diameter u2