


# Data sheet

## PS

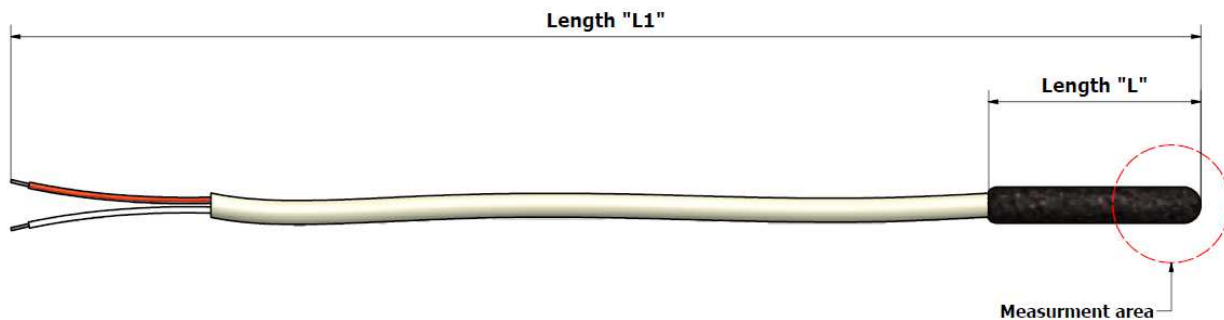

### PT1000 THERMIC ELEMENT WITH CABLE AND OVERMOULDED TIP

**RANGE :**

- -20°C / +100°C

**USE :**

- Universal

**KEY POINT :**

- Flexible

**SPECIFICATIONS :**

- PT1000Ω thermic element A Class – 1x2 wires
- Overmoulded tip
- Cable 2 conductors, section 0.22mm<sup>2</sup>, isolated PVC/PVC

**DIMENSIONS:**

- Tip length = 35mm
- Tip diameter = 6mm
- Total length (tip + cable) = 2020mm

**METROLOGICAL DATA :**

- As per IEC 751
- *Standard tolerance PT100 A class*: ±0.15 + 0.002.[t°C]

Other dimensions:

TIP Diameter	6mm	8mm
Sensing element		
PT100Ω	370-6587	
<b>PT1000Ω</b>	<b>547-7297</b>	
Thermistance	-	370-6133