


PORTABLE STYLE VARIABLE TRANSFORMERS

SAFETY INSTRUCTIONS

1. Read all of these instructions before you use the transformer.
2. This transformer is not designed to provide mains isolation.
3. Variable transformers operate at mains voltage.
DO NOT EXCEED THE MAXIMUM VOLTAGE AND CURRENT RATING.
4. Maintenance should only be carried out by suitably qualified personnel.
5. Variable transformers must not be tested as Class 2 appliances on portable appliances testers, flash test only at 1.5kV.
6. When connected to the electrical supply the terminals, brushes and track face are at mains potential with a potentially lethal voltage.
7. The input must always be applied across the load.
Never connect the transformer in series with the load.
8. The carbon brush should be inspected for damage or wear, faulty or worn brushes will result in damage to the windings.

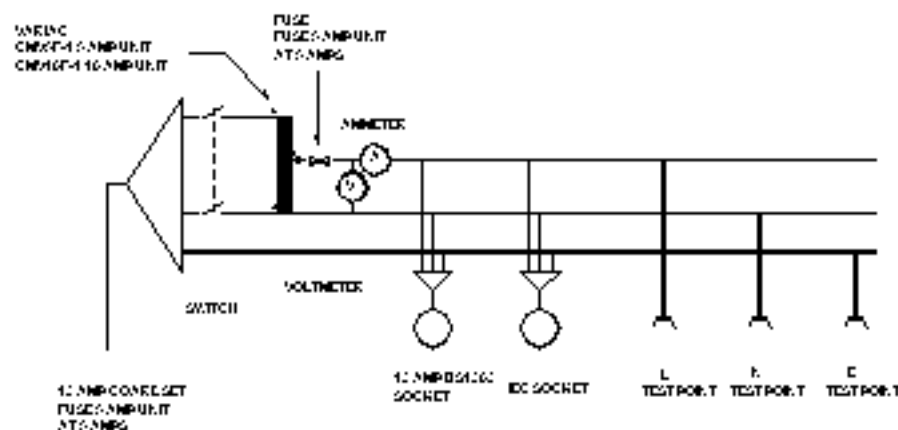

WIRING DIAGRAM

Type	Output Amps	W	D	H	Weight
CMCTV 5	5	210	200	270	10
CMCTV 10	10	210	200	270	12