




Connectors > Contacts > RF Contacts

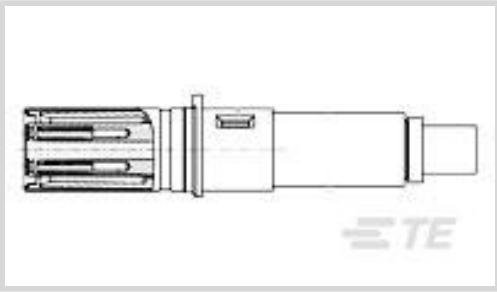

RF Contact Style: **Quadrax**
Contact Type: **Socket**
Connector & Contact Terminates To: **Wire & Cable**
Contact Orientation: **Straight**
Contact Mating Area Plating Material: **Gold (Au)**

Features

Product Type Features

Sealable	Yes
RF Contact Style	Quadrax
Connector & Contact Terminates To	Wire & Cable

Electrical Characteristics

Impedance	100 Ω
-----------	-------

Body Features

Contact Removal Style	Rear Release/Rear Remove
-----------------------	--------------------------

Contact Features

Contact Base Material	Copper
Contact Length	33.83 mm[1.331 in]
Contact Type	Socket
Contact Orientation	Straight
Contact Mating Area Plating Material	Gold (Au)
Contact Current Rating (Max)	1 A

Termination Features

Termination Method to Wire & Cable	Hex Crimp
------------------------------------	-----------

Mechanical Attachment

Contact Retention Type Within Housing	Retention Clip
---------------------------------------	----------------



Dimensions

Wire Size	24 AWG
-----------	--------

Usage Conditions

Operating Temperature Range	-65 – 125 °C[-85 – 257 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Signal
---------------------	--------

Identification Marking

Contact Color Code	None
--------------------	------

Packaging Features

Packaging Method	Package
------------------	---------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) SVHC > Threshold: Pb (3.7% in 74019106) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

TE Part # 1976593-6

TOOLS, INS, GB & GA QUADRAX

TE Part # 1976924-1

TOOL, PLIERS, QUADRAX

TE Part # 1976923-1

KIT, JAW (GB SOCKET)

Customers Also Bought

TE Part # YMC8016-F-13-04SN0

ARINC 801, 38999 STYLE, SIZE 13-04

TE Part # 1918934-3

STD CABLE ADAPTER, No Boot, HA, 5.0 mm

TE Part # ZPF000000000100854

DMC-MD 20 B

TE Part # ZPF000000000137993

787-8055-13M

TE Part # 587763-000

CWT-11-W122-5

TE Part # 1445693-3

SOCKET CONTACT,QUADRAX,SZ8,RR

TE Part # 1-640721-0

06P UMNL STR/REL & INSRT NATL

TE Part # 1445693-4

BACC47GB1 - SCKT CONTACT, QUADRAX,SZ8,RR

TE Part # 605704-ZZ

CONT SKT.SIZE 24.

TE Part # Y323-1111-00-00000

26PIN MALE HIGH DENSITY D-CONNECTOR WIRE

Documents

Product Drawings
SOCKET CONTACT,QUADRAX,SZ8,RR
English

CAD Files
3D PDF



3D

Customer View Model

[ENG_CVM_CVM_1445693-1_P.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1445693-1_P.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1445693-1_P.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[DEUTSCH MIL-DTL-38999 CIRCULAR CONNECTORS](#)

English

Product Specifications

[Application Specification](#)

English

[Application Specification](#)

English