


## S.T – 1/2” 6 Point OGV Sockets

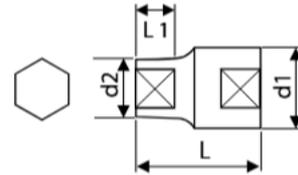

### Description:

- 6 Point OGV profile – Higher Grip and Torque without damaging the fasteners
- Chrome Plated Satin Finish – improves corrosion resistance
- For Manual Use
- ISO 2725-1 - DIN 3124 - ISO 1174-1 - ISO 1711-1 - ISO 691

	Socket Size A	D1mm	D2mm	L mm	L1mm	Weight
S.8HT	8	21.8	12.4	38	9	45
S.9HT	9	21.8	14	38	10	45
S.10HT	10	21.8	15.5	38	10	48
S.11HT	11	21.8	16.7	38	10	50
S.12HT	12	21.8	18	38	10	50
S.13HT	13	21.8	19.2	38	10	52
S.14HT	14	21.8	20.5	38	10	54
S.15HT	15	21.8	21	38	14	54
S.16HT	16	23.3	22.5	38	14	66
S.17HT	17	24	24	38	14	76
S.18HT	18	24.8	24.8	38	14	84
S.19HT	19	26.3	26.3	38	16.7	84
S.20HT	20	26.8	26.8	38	17.3	84



S.21HT	21	27.7	27.7	38	18	92
S.22HT	22	29.8	29.8	40	18	118
S.23HT	23	30.8	30.8	40	18	125
S.24HT	24	31.8	31.8	40	18	134
S.25HT	25	32.8	32.8	41	20	142
S.26HT	26	33.8	33.8	41	20	160
S.27HT	27	35.8	35.8	41	20	192
S.28HT	28	37.6	37.6	41	20	220
S.29HT	29	37.8	37.8	41	20	220
S.30HT	30	39.8	39.8	41	20	234
S.32HT	32	41.8	41.8	41	20	266