

STYLEA

5920UOI035L51-10 LOW

EAN 4031582356731

Swivel castor, housing made of Polyamide, with blind hole fitting. Wheel centre made of Polyamide, plain bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Technical Data

Wheel diameter	35 mm
Wheel width	12 mm
Castor width	52 mm
Centre hole	10 mm
Dome-Ø	15.2 mm
Offset	12 mm
Swivel Interference	74 mm
Overall height	33 mm
Temperature	- 20 / + 60 °C
Standard	EN_12528
Weight	0.047 kg
Swivel Radius	37 mm
Load capacity	50 kg
Load capacity (static)	100 kg

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ●
Corrosion resistance	● ● ● ● ○

Dimensions

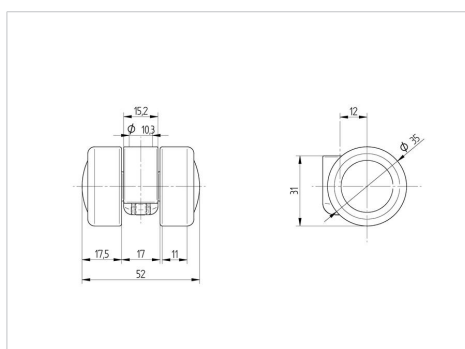

Structure & Mounting

