


ACCESSORIES RANGE

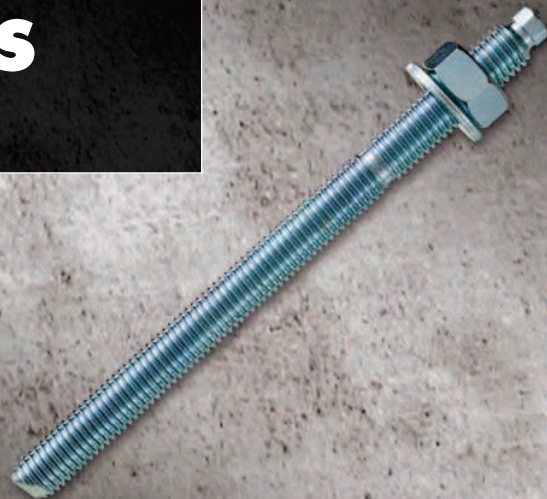

PUMP



Cat No.	Description	Pack Quantity	Carton Quantity
DFC1650050	DEWALT Blow Pump	1	1

STEEL BRUSHES AND SDS EXTENSIONS



DFC1670000



DFC1670300



DFC1670050



DFC1670200




DFC1670500

Cat No.	Description	Length [mm]	Drill Dia. [mm]	Rebar Size [mm]	Thread Size [mm]	Pack Quantity	Carton Quantity
DFC1670000	SDS Connection for Steel Brushes	-	-	-	-	1	20
DFC1670050	300MM Extension for Steel Brushes	300	-	-	-	1	20
DFC1670100	Steel Brush for SDS - 12MM Diameter	170	10	Ø8	M8	1	10
DFC1670150	Steel Brush for SDS - 14MM Diameter	170	12	Ø10	M10	1	10
DFC1670200	Steel Brush for SDS - 16MM Diameter	200	14	Ø12	M12	1	10
DFC1670250	Steel Brush for SDS - 18MM Diameter	200	16	Ø14	-	1	10
DFC1670300	Steel Brush for SDS - 20MM Diameter	300	18	Ø16	M16	1	10
DFC1670350	Steel Brush for SDS - 22MM Diameter	300	20	Ø20	-	1	10
DFC1670400	Steel Brush for SDS - 26MM Diameter	300	24	Ø20	M20	1	10
DFC1670450	Steel Brush for SDS - 30MM Diameter	300	28	Ø25	M24	1	10
DFC1670500	Steel Brush for SDS - 34MM Diameter	300	32	Ø28	M27	1	10
DFC1670550	Steel Brush for SDS - 37MM Diameter	300	35	Ø32	M30	1	10
DFC1670600	Steel Brush for SDS - 40MM Diameter	300	37	-	-	1	10

THREADED ROD - CHISEL POINT


- Vinyl ester spinning capsules also suitable for diamond drilled holes

 THREADED ROD CHISEL POINT - 5.8 GALVANISED STEEL



Cat No.	Description	Length [mm]	Drill Dia. [mm]	Thread Size [mm]	Pack Quantity	Carton Quantity
DFC4100000	Chisel Point Threaded Rod STM8x110-5.8Glv w/Nt&Wsh	110	10	M8	25	500
DFC4100050	Chisel Point Threaded Rod STM10x130-5.8Glv w/Nt&Wsh	130	12	M10	25	500
DFC4100100	Chisel Point Threaded Rod STM12x160-5.8Glv w/Nt&Wsh	160	14	M12	10	200
DFC4100150	Chisel Point Threaded Rod STM16x190-5.8Glv w/Nt&Wsh	190	18	M16	10	40
DFC4100200	Chisel Point Threaded Rod STM20x240-5.8Glv w/Nt&Wsh	240	24	M20	10	40
DFC4100250	Chisel Point Threaded Rod STM24x290-5.8Glv w/Nt&Wsh	290	28	M24	10	40

 THREADED ROD CHISEL POINT - ZINC PLATED CLASS 5.8 STEEL



Cat No.	Description	Length [mm]	Drill Dia. [mm]	Thread Size [mm]	Pack Quantity	Carton Quantity
DFC4130000	Chisel Point Threaded Rod STM8x110-5.8Stl w/Nt&Wsh	110	10	M8	10	200
DFC4130050	Chisel Point Threaded Rod STM10x130-5.8Stl w/Nt&Wsh	130	12	M10	10	200
DFC4130100	Chisel Point Threaded Rod STM12x160-5.8Stl w/Nt&Wsh	160	14	M12	10	100
DFC4130150	Chisel Point Threaded Rod STM16x190-5.8Stl w/Nt&Wsh	190	18	M16	10	40
DFC4130200	Chisel Point Threaded Rod STM20x260-5.8Stl w/Nt&Wsh	260	24	M20	5	20
DFC4130250	Chisel Point Threaded Rod STM24x300-5.8Stl w/Nt&Wsh	300	28	M24	5	20

THREADED ROD CHISEL POINT - A4 STAINLESS STEEL



Cat No.	Description	Length [mm]	Drill Dia. [mm]	Thread Size [mm]	Pack Quantity	Carton Quantity
DFC4150000	Chisel Point Threaded Rod STM8x110 A4SS w/Nt&Wsh	110	10	M8	10	200
DFC4150050	Chisel Point Threaded Rod STM10x130 A4SS w/Nt&Wsh	130	12	M10	10	200
DFC4150100	Chisel Point Threaded Rod STM12x160 A4SS w/Nt&Wsh	160	14	M12	10	100
DFC4150150	Chisel Point Threaded Rod STM16x190 A4SS w/Nt&Wsh	190	18	M16	10	40
DFC4150200	Chisel Point Threaded Rod STM20x260 A4SS w/Nt&Wsh	260	24	M20	5	20
DFC4150250	Chisel Point Threaded Rod STM24x300 A4SS w/Nt&Wsh	300	28	M24	5	20