




Data Specification Sheet

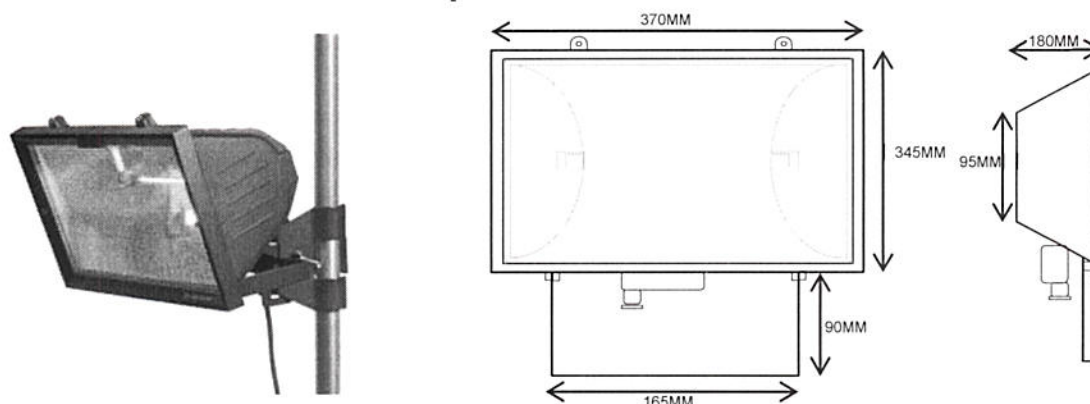

HEOD1309BK 1300W Infrared Heater

ML Accessories Code	HEOD1309BK HEOD1309W
Description	IP24 Halogen Floodlight
Base Finishes available	Black or White
Overall dimensions (mm)	See above diagram
Fixing	Stirrup Bracket or Pole Mount Fixing (Supplied)
Typical location	Indoor or Outdoor (Not suitable for food preparation areas)
Lamp Supplied	Yes – HEOT1300W
Voltage (V)	220-230V 50Hz
Wattage (W)	1300W Max
Circuit Watts	1300W
Class	Class I. Must be Earthed
IP	IP24
Photometric Testing	N/A
Instruction sheet	Yes
Origin of manufacture	China
Pack Included	Instructions
Main materials:	
• Body	Die-cast
• Reflector	Aluminium
• Gasket	Silicone Rubber
• Front Cover	Steel Mesh Grill
Lamp holder cap and make	RX7 Kang Rong
Lamp type	HEOT1300W – 1300W Infrared Ruby 240V
Electrical Connections	3 meters HO5RN-F 3 core 1.5mm ² cable c/w 13A BS Rubber plug
Dimmable	N/A
Distance from flammable object	2.mtrs
CE mark	Yes
Quality Assurance System	Yes ISO 9001 QMS
Batch coding details	Yes
Certificate of Conformity	Yes
Manufactured in accordance	BSEN
Guarantee Period	1 Year

ML Accessories Ltd. reserves the right to withdraw, improve or modify any design without prior notification.

ML Accessories Ltd. cannot be held responsible for the incorrect application of any product.

ISSUE PS-01-12-V001 SC-02