



Attached lid containers


400 x 300

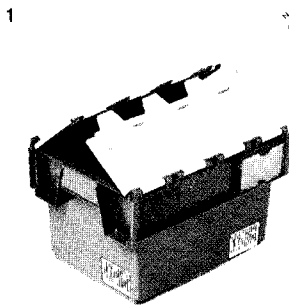


1 20 litres - Ref. 10020
polypropylene
complete with integral hinged lid
Ext. dim.: L 400 X w 300 X h 252 mm
Ext. dim.: L 15.8 X w 11.8 X h 9.9"
Int. dim.: L 325 X w 246 X h 222 mm
Int. dim.: L 12.8 X w 9.7 X h 8.6"
nested height: 100 mm/4"
Wt: 1.73 kg/3.8 lbs.
Colour: dark green / light green.

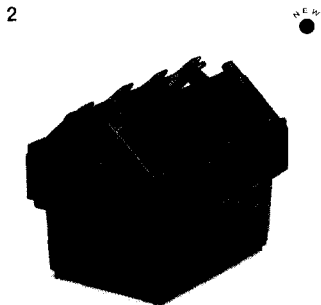


2 20 litres - Ref. 10022
polypropylene
As ref. 10020 without recessed base
Colour: blue.

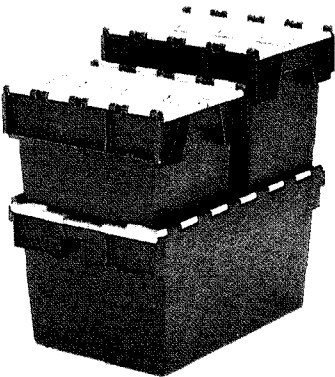


Containers ref. 10020 & 10025 stacked on
600 X 400 Attached Lid Container.

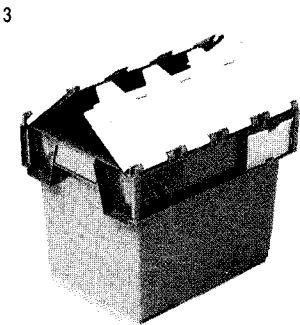


3 25 litres - Ref. 10025
polypropylene
complete with integral hinged lid
Ext. dim.: L 400 X w 300 X h 320 mm
Ext. dim.: L 15.8 X w 11.8 X h 12.6"
Int. dim.: L 321 X w 244 X h 295 mm
Int. dim.: L 12.6 X w 9.6 X h 11.6"
nested height: 100 mm/4"
Wt: 2.5 kg/5.5 lbs.,
Colour: dark green/ light green.

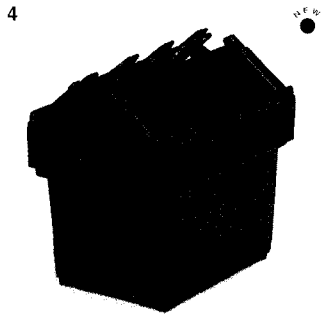


4 25 litres - Ref. 10027
polypropylene
As ref. 10025 without recessed base
Colour: blue.

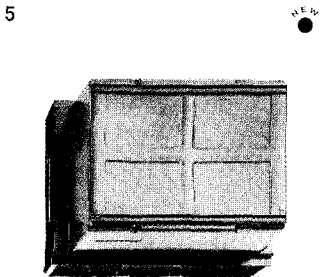

 
5 Ref. 10020 & 10025
Recessed base of containers ref.
10020 & 10025 allow stacking two-
up on 600 X 400 mm Allibert Attached
Lid Containers.




6 Ref. 10022 & 10027
Flat base of containers ref. 10022 &
10027 for smooth internal base - will
not stack on 600 X 400 mm Attached
Lid Containers.

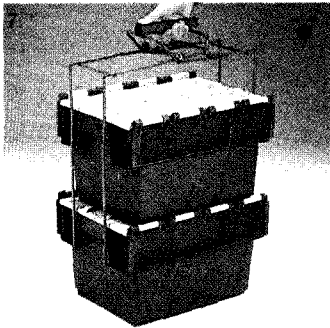


7 Ref. 00609
Attached Lid Container carrier
Enables user to carry two stacked (or
four nested) 400 X 300 containers,
leaving one hand free for opening
doors, etc.
For containers ref. 10020, 10022, 10025
& 10027.

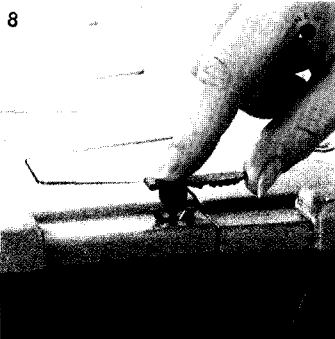

8 Ref. 00501
polypropylene
Security seal for containers ref. 10020,
10022, 10025, 10027, 10040, 10050,
10061, & 10125
(supplied in bags of 500).



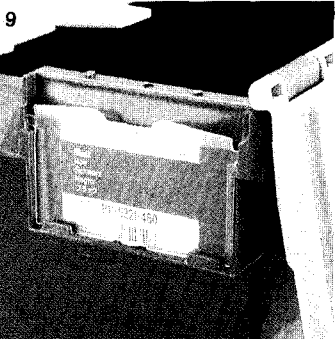


9 Ref. 00473
label holder in K resin for containers ref.
10020, 10022, 10025, 10027, 10040,
10050, 10061 & 10125.

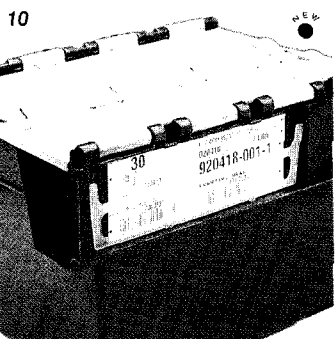

10 Ref. 00509
document holder in K resin for containers
ref. 10020, 10022, 10025 & 10027.

600 x 400

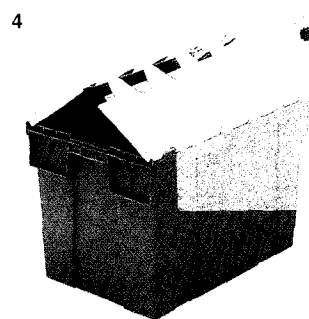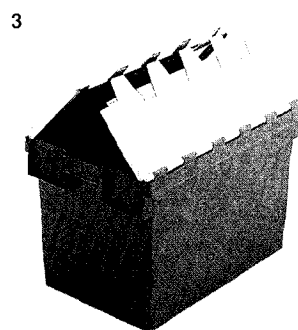
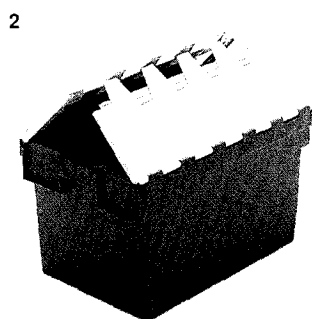


polypropylene
complete with integral hinged lid
Ext. dim.: 1 600 X w 400 X h 250 mm
Ext. dim.: 1 23.6 X w 15.8 X h 9.9"
Int. dim.: 1 515 X w 343 X h 215 mm
Int. dim.: 1 20.3 X w 13.5 X h 8.5"
nested height: 85 mm/3.3"
Wt: 2.78 kg/6.2 lbs., Colour: dark green/
light green.

polypropylene
complete with integral hinged lid
Ext. dim.: L 600 X w 400 X h 320 mm
Int. dim.: L 23.6 X w 15.8 X h 12.6"
Ext. dim.: L 508 X w 335 X h 285 mm
Int. dim.: L 20.0 X w 13.2 X h 11.2"
nested height: 85 mm/3.3"
Wt: 3.2 kg/7 lbs., Colour: dark green/
light green.

polypropylene
complete with integral hinged lid
Ext. dim.: L 600 X w 400 X h 365 mm
Int. dim.: L 23.6 X w 15.8 X h 14.4"
Ext. dim.: L 501 X w 328 X h 330 mm
Int. dim.: L 19.7 X w 12.9 X h 13.0"
nested height: 85 mm/3.3"
Wt: 4.3 kg/7.3 lbs., Colour: dark green/
light green.




polypropylene - minimum order item
complete with integral hinged lid
Ext. dim.: L 600 X W 400 X h 385 mm
Ext. dim.: L 23.6 X W 15.8 X h 15.2"
Int. dim.: L 512 X W 329 X h 355 mm
Int. dim.: L 20.2 X W 13.0 X h 14.0"
nested height: 115 mm/4.5"
Wt: 3.9 kg/8.6 lbs.
Color: light green/ light green

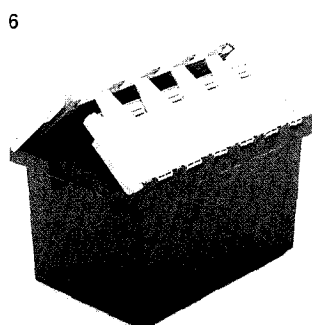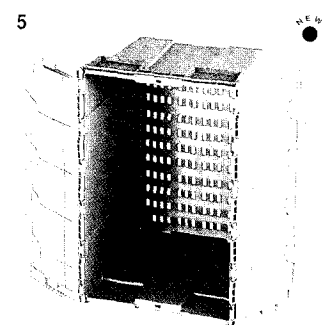

minimum order item
polypropylene
as container ref. 10066 with ventilated
base.
Wt: 3.85 kg/8.5 lbs.
Colour: dark green / light green.

polypropylene
with 4 drainage holes in base
complete with integral hinged lid
Ext. dim.: 1 720 X w 460 X h 365 mm
Ext. dim.: 1 28.4 X w 18.1 X h 14.4"
Int. dim.: 1 597 X w 374 X h 318 mm
Int. dim.: 1 23.5 X w 14.7 X h 12.5"
nested height: 80 mm/3.1"
Wt: 4.7 kg/10.4 lbs.. Colour: dark green/
light green.

minimum order item
polypropylene
as ref. 10080 without
drainage holes.

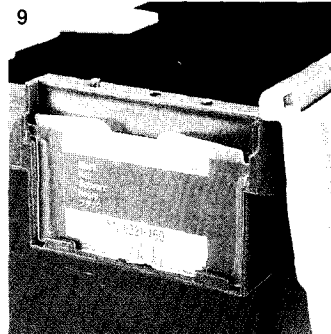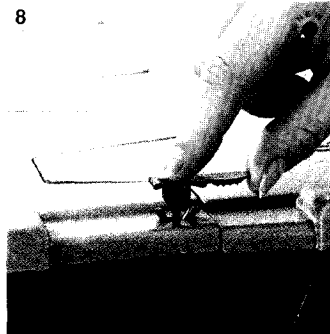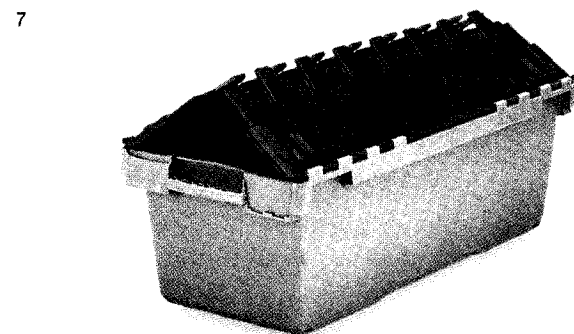

polypropylene
complete with integral hinged lid
Ext. dim.: L 1,160 X w 480 X h 360 mm
Ext. dim.: L 45.7 X w 18.9 X h 14.2"
Int. dim.: L 1,000 X w 370 X h 332 mm
Int. dim.: L 39.4 X w 14.6 X h 13.0"
nested height: 80 mm/3.15"
Wt: 7.4 kg/15.6 lbs.
Colour: grey / orange.

polypropylene
Security seal for containers ref. 10020,
10022, 10025, 10027, 10040, 10050,
10061 & 10125.
(supplied in bags of 500)

label holder in K resin for containers ref. 10020, 10022, 10025, 10027, 10040, 10050, 10061 & 10125.