

Previously known as: MICROCHEM® 3000 Overshoes - Model 400

Comfortable and lightweight safety footwear, providing a multi-layer chemical barrier.

- **Specialized protection:** Composed of protective multi-layer barrier fabric, AlphaTec™ 3000 Overshoes Ultrasonically Welded & Taped - Model 400 affords superb resistance against inorganic chemicals and biological hazards
- **Heightened visibility:** Bright yellow in color, these overshoes not only offer chemical resistance but also high visibility in dark environments to boost worker safety
- **Lightweight feel and improved durability:** In addition, they are among the most comfortable, lightweight and robust protective footwear on the market



Industries

- Mining
- Food Processing
- Energy
- Chemical
- Automotive Aftermarket
- Infrastructure Maintenance

Applications

- Unexpected leakages spills or other releases
- Transferring liquids and solids
- Spill or leakage cleanup
- Plant disinfection and sanitization
- Maintenance
- Emergency Response
- Contaminated Environments
- Tank Cleaning


KEY FEATURES & BENEFITS

- ◊ **Multi-layer barrier fabric:** For chemical-resistant work footwear
- ◊ **Highly visible bright yellow color:** Reduced workplace injuries
- ◊ **Lightweight and durable:** Flexible and long-lasting personal protection


Technology



Material Diagram

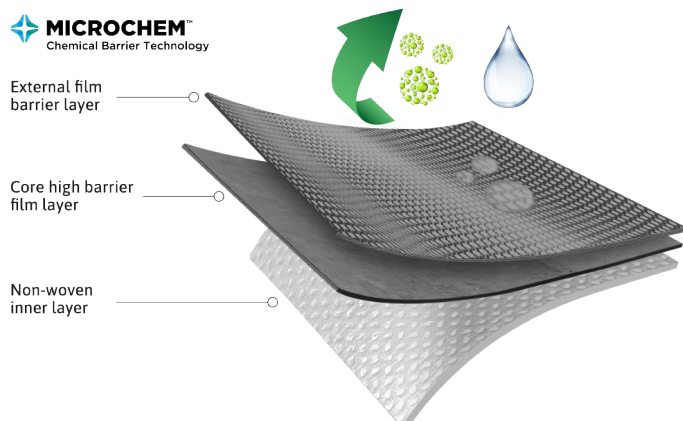

Seam Diagram

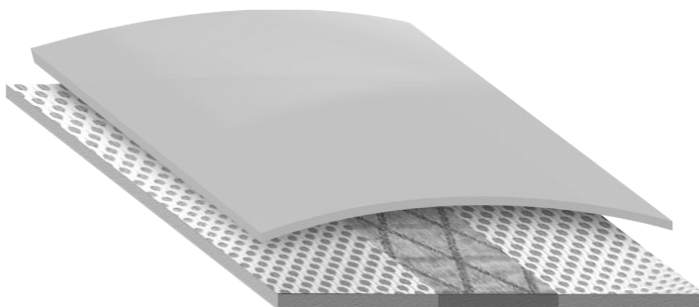

Performance Standards


0598


EN 14126

EN ISO 13688:2013


PARTIAL BODY
PROTECTION ONLY


TYPE PB [3]


TYPE PB [4]


TYPE PB [6]

Product Information

Product Information	
Available Sizes	One Size
Color	Yellow
Packaging Overview	50 PR in a compressed bag
Product Material	Multi-layer non-woven barrier Laminate fabric
Product Reference	3000 Overshoes - Model 400
Standards Overview	CE CATEGORY III (Type PB [3]-B, Type PB [4]-B, Type PB [6]-B, EN 14126
Seam Type	Welded and Taped
Shelf Life	5 years
Style Number	Y30T400

Suit components & accessories

Suit Components and Accessories	
Design Features	Overshoes, elasticated opening

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region
Ansell Healthcare Europe NV
T: +32 (0) 2 528 74 00

North America Region
Ansell Healthcare Products LLC
T: +1 800 800 0444

Australia
Ansell Limited
T: +61 1800 337 041

Asia Pacific Region
Ansell Global Trading Center
T: +603 8310 6688

Latin America & Caribbean Region
Ansell Commercial Mexico S.A. de C.V.
T: +52 442 248 1544 / 248 3133

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

