



Technical data

KRV12LLH/3AS

Cam follower with shaft

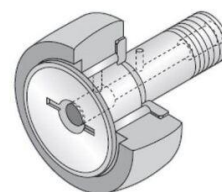

VISUAL (S)

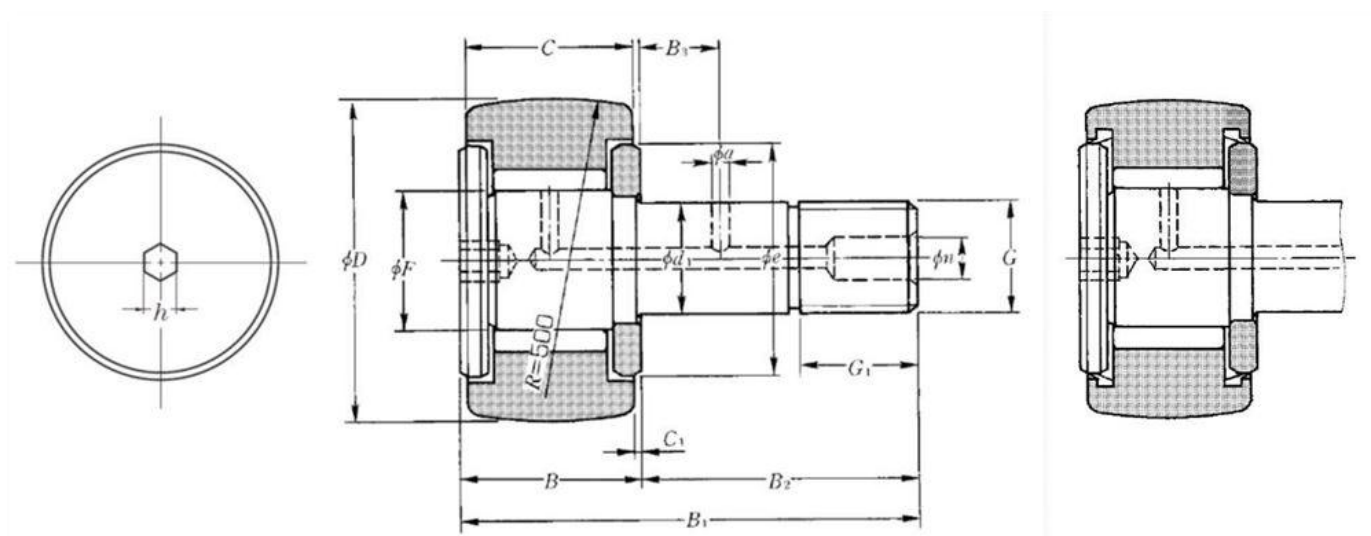

PRODUCT DEFINITION

Brand	NTN
D - External diameter	12 mm
d1 - Stud diameter	4 mm
C - Width of bearing, drawn cup or outer ring	8 mm
F - Under roller diameter	4,8 mm
B - Bearing/Inner ring width	9 mm
B1 - Total stud length	20 mm
B2 - Stud rod length	11 mm
G - Stud thread designation	M4X0.7



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

G1 - Thread length of the stud	6 mm
C1 - Distance between roller face and washer face	0,5 mm
e - Inlet diameter of roller or washer	8,5 mm
h - Hexagonal hole	2,5 mm
R - Track roller radius	500 mm
Maximum tightening torque	1 N-m
Bearing with/without cage	Sans
Radial clearance class	CN
Precision class	P0
Mass	0,008 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	3,5 kN
C0r - Static load rating	3,8 kN
Track load capacity spherical outer ring	0,725 kN
N lim - Grease lubrication limit speed	10000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	100 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	KRV12LLH/3AS
Image	NRBKRV_LLH_1.jpg, NRBKRV_LLH_3.jpg
Rolling element material	Acier 100Cr6

