


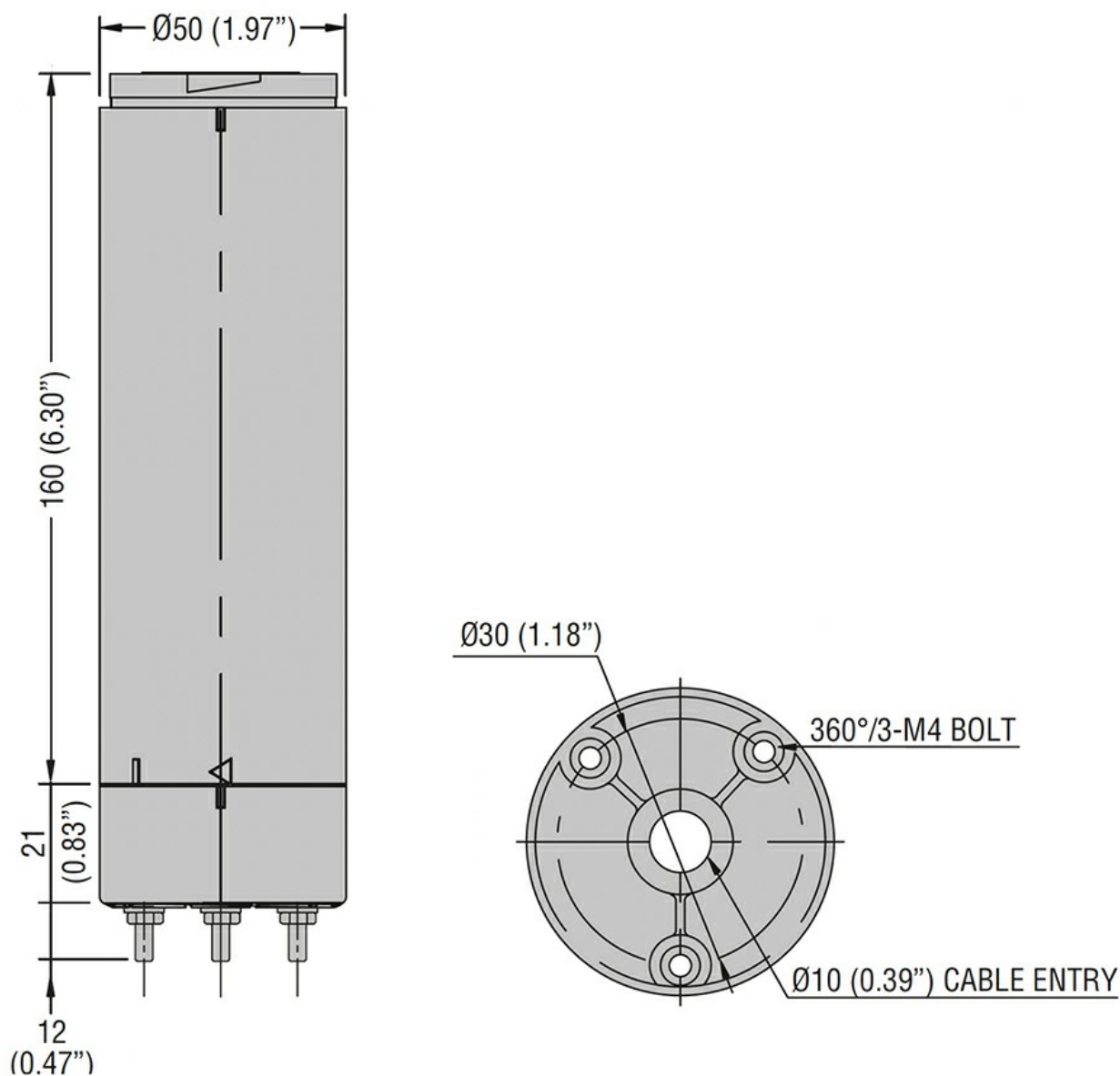

General characteristics				
Diameter		mm - inch		50 / 1.97
Supply voltage (AC)		V		110...230
IEC degree of protection		IP65		
Power consumption		VA		1
Mechanical features				
Terminals screw		Spring terminals		
Conductor section				
AWG/Kcmil		min		16
		max		24
IEC		min		mm ² 0.25
		max		mm ² 1.5
Weight		g		222
Ambient conditions				
Temperature				
Operating temperature		min		°C -30
		max		°C +50
Dimensions				



Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN/BS 60947-1

IEC/EN/BS 60947-5-1

UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC001154 -
Stand for signal
tower without
tube