


Technical Information

Tecno Line

Code	76S-000000000001
Name	Cabinet for flammable liquids monobloc
Dimensions (WxDxH)	1000x450x1000 mm
Comp. Dim. (WxDxH)	998x430x900 mm
N° places	1
N° comp. per column	1
Material	DC01/FeP01 UNI EN 10130
Weight (Kg)	33
Volume (m3)	0,45

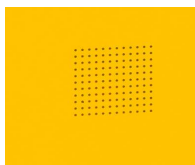

General features

Base and body	Base on steel socle, h. 100 mm. Body formed by electro-welded paneling 8/10 thick, Bottom, top, back, sides with racks front thickness 30 mm and refolded edges .ventilation on the top.
Doors	Hinged doors with 180° rotation angle, reinforcement and three times refolded anti-cut edges, labels compliant with regulations.
Lock	Cylinder lock with double key
Closing	2-points closing lever
Internal construction	N °1 Storage tank for 28 litres and 1 shelf 30 mm high, adjustable on rack, complete with galvanised steel shelf supports for holding up to 11 Lt.
Door color	Epoxy powder painting color Ral 1003
Body color	Epoxy powder painting color Ral 1003
Law	In specification D.Lgs.81/2008, EN UNI ISO 9001, EN UNI ISO 14001, UNI tests on product and finishing.

Configuration variants

Doors	Without ventilations
Locks	Padlock

Accessories

Movable tray shelf on rack supplied with galvanized shelf brackets

Spare parts

Cylinder lock supplied with double key

Left or right hinged door H. mm. 870

Certifications

Check the list of certifications available in the appropriate section of the website or ask our commercial offices.

This technical sheet is exclusive property of Armet Srl.

Reproduction is forbidden within the law (art.171 Law 22/04/1941 ,n.633).

The fraudulent use, without proper written authorization, even partial and by whatever means, will be protected according to law.

The foregoing text contains information reserved to the intended recipient.

The content of this e-mail is confidential and its confidentiality is legally protected by DL196/03