



Cut protection

KRYTECH 642

Low risk - ISO B



CUT PROTECTION
LEVEL B



4X42B



X1XXXX

CATEGORY 2



ISO 13997:
5,7 N

DEXTERITY
EN ISO 21420:
5/5



Comfort, Suppleness & breathability without any compromise on cut protection & durability
Can be used with touch devices & touch screen.

SPECIFIC ADVANTAGES



Comfort

- A seamless plaited glove for a maximum comfort, dexterity and flexibility while providing optimal cut protection (Cut level ISO B)



Durability

- Extended use guaranteed by our exclusive process RESICOMFORT. Proven breathability, flexibility and durability of the coating.



Skin protection

- Free of harmful substances: OEKO-TEX® STANDARD 100, DMF Free
- Dermatologically approved



Suitable for touchscreen

- Can be used with touch devices & touch screen



Guaranteed quality

- Silicone free to prevent traces, defects on metal sheet and glass prior to painting



Washability

- Washable 1 time at 40°C



Practical

- Cut level easy to identify thanks to the marking on the back of the glove.

INDUSTRIES

- Automotive/mechanical industry
- Construction Industry (Carpenters/Joiners)
- Construction Industry (Roofers/Tilers/Glaziers)
- Construction Industry (Heating engineers/Plumbers)
- Paper industry

APPLICATIONS

- Installing steel structures
- Assembly
- Screwing
- Laying tiles, inserts, frames or zinc sheeting
- Handling metal parts
- Handling cardboard and paper
- Handling and sorting small, sharp parts





Cut protection

KRYTECH 642

Low risk - ISO B

LEGENDS

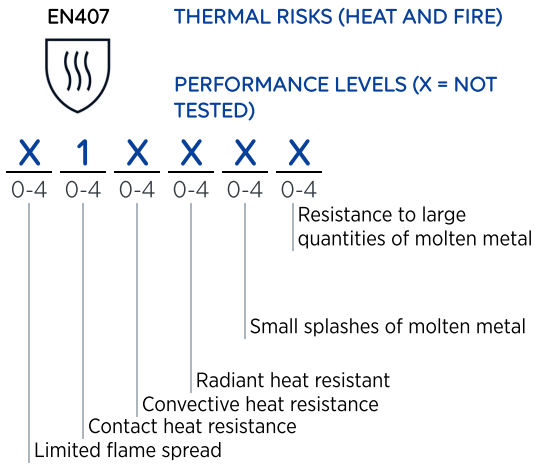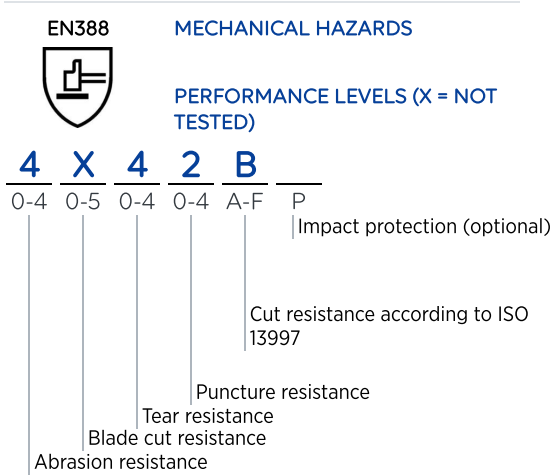

PRODUCT DETAILS

Interior finish	Seamless textile support from HDPE fibres
Gauge	15
Exterior finish	Reinforced grip
Material	Nitrile foam sandy
Cuff characteristic	Knitted Cuff
Colour.s	Black Grey
European sizes	6 7 8 9 10 11

LOGISTIC DETAILS

Packaging	1 pair/bag 12 pairs/bag 48 pairs/carton
-----------	---

LEGISLATION

- This product is not classified hazardous according to the regulation (EC) n°1272/2008 of the European Parliament and of the Council.
- This product does not contain more than 0.1 % of substance of very high concern (SVHC) or any substance included in the annex XVII of the regulation n° 1907/2006 of the European Parliament and of the Council (REACH).
- UE type certificate or CE type examination certificate: 0075/014/162/10/20/2585
- Issued by the notified body nr: 0075 CTC - 4, rue Hermann Frenkel - 69367 Lyon Cedex 07- FRANCE