

HVLP water-based spray gun



Technical characteristics

Technology: Suction feed or gravity


Construction: Body : Aluminium,
Needle and nozzle : Stainless steel

Applications: Automotive and industrial sectors

Highlight: Three types of adjustment (width of stream, paint flow rate and air flow rate)

BSPP female thread: G 1/4

Aluminium body
0,6 litre polyamid cup
Stainless steel needle and nozzle
Pressure for an optimum spraying: 2 bar
Max. Pressure: 3 bar
Air consumption: 285 l/min under 3 bar
Weight: 600 g
G 1/4 M connection
M16 x 1,5 P cup connection thread

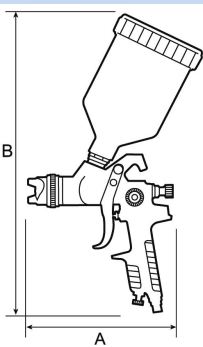

A (mm)	B (mm)	Nozzle Ø (mm)	Parts Numbers
165	330	1.3	CAR G04HVW