



### Preformati ad angolo retto, VG style


- Helashrink serie 1100, con labbro

#### Caratteristiche del prodotto


- Combinato con un adattatore scanalato riduce gli stress interni
- Si restringe con un angolo di 90 gradi



Preformato 1152-4-G ristretto su di un connettore.

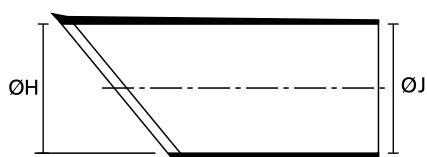

a: espanso (come fornito)

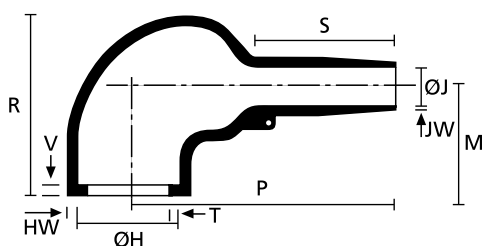

b: completamente ristretto



Preformato 1152-4 espanso (come fornito).

Per informazioni in merito al  
Materiale / Adesivo vedi pag. 200.

ARTICOLO	ØH min. a	ØH max. b	ØJ min. a	ØJ max. b	P ± 10%	R ± 10%	HW ± 20%	JW ± 20%	V ± 10%	T ± 20%	M nom.	S nom.	Realizzato per Norma-VG	UNS
1152-4-G	24,0	10,5	24,0	6,0	26,0	25,0	1,3	0,5	3,0	1,0	19,0	10,0	VG95343T06E001A	411-52480
1154-4-G	30,0	15,5	30,0	6,0	32,0	27,0	1,5	0,8	3,0	1,0	19,0	12,0	VG95343T06E002A	411-54480
1155-4-G	31,0	18,0	31,0	7,0	40,0	31,0	1,8	1,0	3,0	1,0	21,0	15,0	VG95343T06E003A	411-55480
1156-4-G	36,0	22,5	36,0	8,5	46,0	38,0	1,8	1,0	3,0	1,0	26,0	15,0	VG95343T06E004A	411-56480
1157-4-G	43,0	28,5	43,0	10,0	55,0	45,0	2,0	1,0	3,0	1,7	30,0	16,0	VG95343T06E005A	411-57480
1158-4-G	60,0	35,0	60,0	16,0	80,0	54,0	3,3	1,5	3,0	1,7	35,0	30,0	VG95343T06E006A	411-58480
1159-4-G	66,0	45,0	66,0	17,0	108,0	68,0	3,8	2,0	3,0	2,0	42,0	51,0	VG95343T06E007A	411-59480
1160-4-G	82,0	61,0	82,0	25,0	118,0	84,0	4,0	4,0	3,0	2,0	52,0	39,0	VG95343T06E008A	411-60480

Tutte le dimensioni sono in mm. Soggette a modifiche tecniche.

Questi preformati termorestringenti sono disponibili in un'ampia gamma di materiali / adesivi. Per maggiori informazioni consulta il catalogo Moulded Shapes.



Per certificazioni specifiche sul prodotto, fate riferimento all'Appendice.