


## LED Bulkhead with dimming sensor



| MLA part code                            | TPB14LEDA                            |
|------------------------------------------|--------------------------------------|
| Description                              | 14W LED Bulkhead with dimming sensor |
| Weight (kg)                              | 1.25                                 |
| Wattage (W)                              | 14                                   |
| Overall dimensions (mm)                  | 330 (diameter) 110 (projection)      |
| Lumens (lm)                              | 1070                                 |
| Efficacy (lm/W)                          | 76                                   |
| Power Factor                             | >0.9                                 |
| Operating current (mA)                   | 65                                   |
| CRI                                      | >80                                  |
| CCT                                      | 6000K                                |
| LED Colours                              | Daylight                             |
| Dimming level                            | 10-100%                              |
| Input voltage                            | Mains 230V 50Hz                      |
| Construction                             | Polycarbonate                        |
| Class                                    | Class II                             |
| IP rating                                | IP44                                 |
| Lifespan (hrs)                           | 30,000                               |
| Warranty                                 | 3 Years                              |
| Dimmable                                 | No                                   |
| Origin of Manufacture                    | China                                |
| Quality assurance system                 | ISO9001                              |
| Declaration of Conformity (held on file) | Yes                                  |
| Manufactured in accordance with          | EN60598                              |

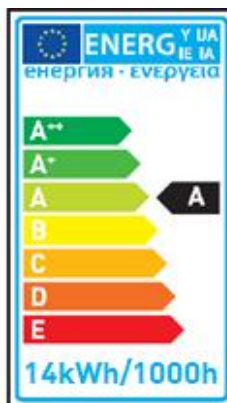