



PRODUCT DATASHEET

Amelia series

last update 12/6/2014


DETAILS

Product Number	CP13512_AMELIA-S
Family	Amelia
Type	Assembly
Color	white
Diameter	45 mm
Height	27,1 mm
Style	round
Optic Material	PC
Holder Material	PC
Fastening	socket
Status	ready
ROHS Compliant	Yes
Date Updated	12/06/2014



OPTICAL PROPERTIES

	Viewing	Light	Effi-		
LED	Angle	Beam	ciency	cd/lm	Connector
LUXEON S1000	14 deg	Spot	93 %	10.000	-

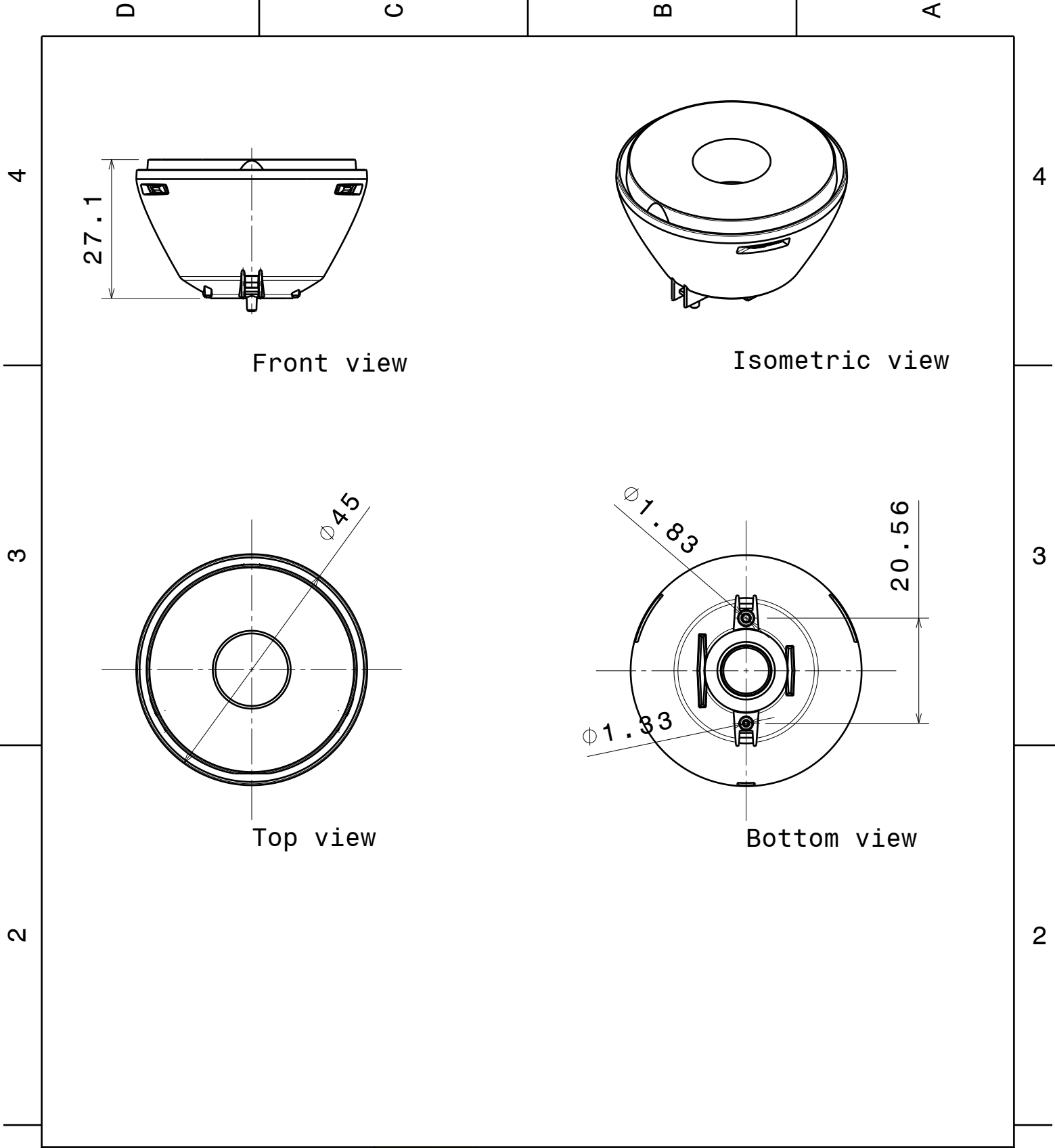


Tolerances if not otherwise shown According to DIN ISO 2768-1 Linear measures: Up to 30mm class M, otherwise class C. According to DIN ISO 2768-2 Form and position: class L		<div>LEDiL</div> <div>Ledil Oy Salorankatu 10 FIN 24240 SALO Finland</div>			
THIRD ANGLE PROJECTION: 		DRAWING TITLE AMELIA-S Mechanical Model			
This drawing is the property of LEDiL Oy. It may not be reproduced, copied or communicated without a written agreement with LEDiL Oy."		SIZE	PART NUMBER		
		A4	-		
		SCALE	1:1	WEIGHT	-
				SHEET	1 / 1


D

A

Luminaire: LEDiL Oy CP13512_AMELIA-S_(LUXEON_S)
Lamps: 1 x LUXEON_S_517.632lm@250mA_P=6.38514W_I=249.8mA

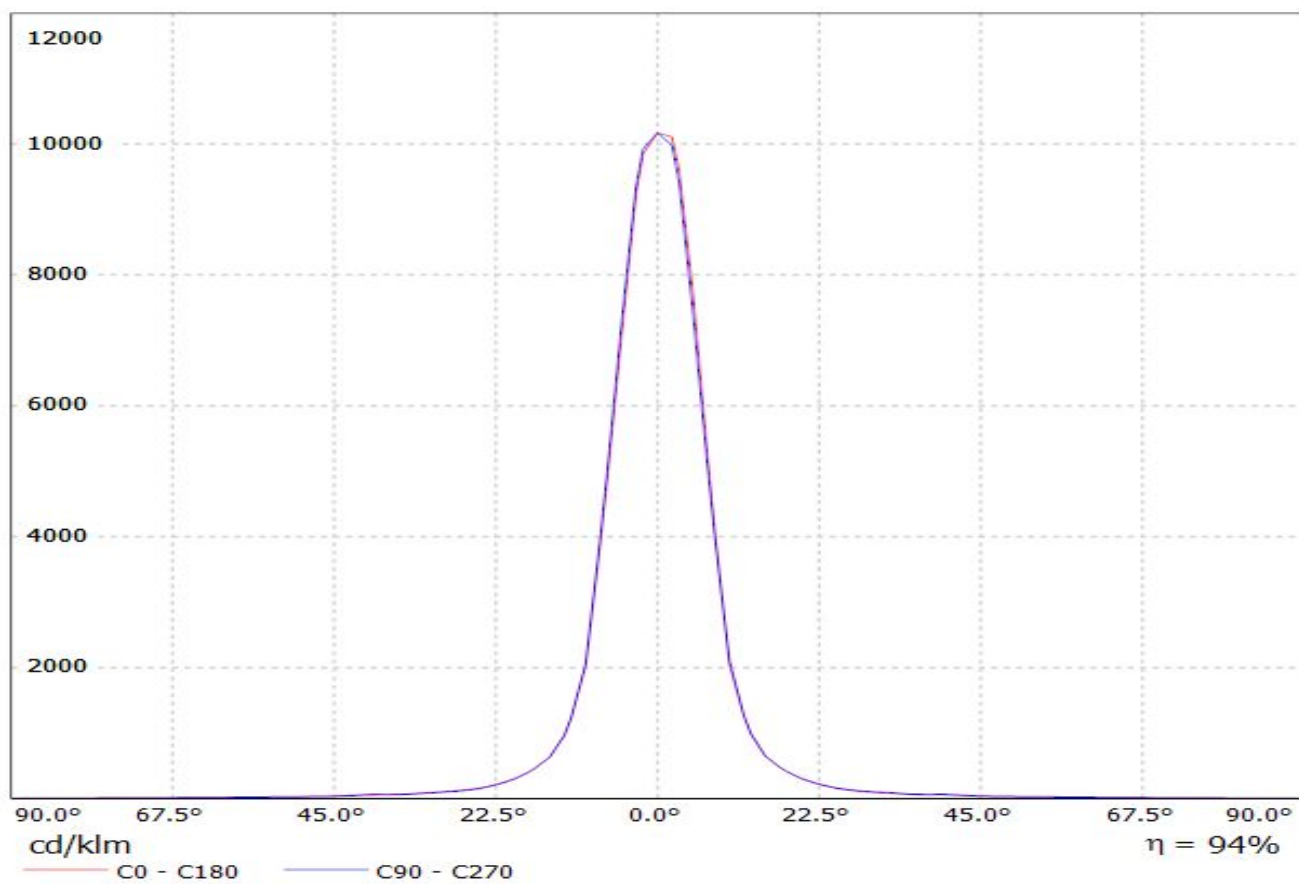

Luminaire: LEDiL Oy CP13512_AMELIA-S_(LUXEON_S)
Lamps: 1 x LUXEON_S_517.632lm@250mA_P=6.38514W_I=249.8mA

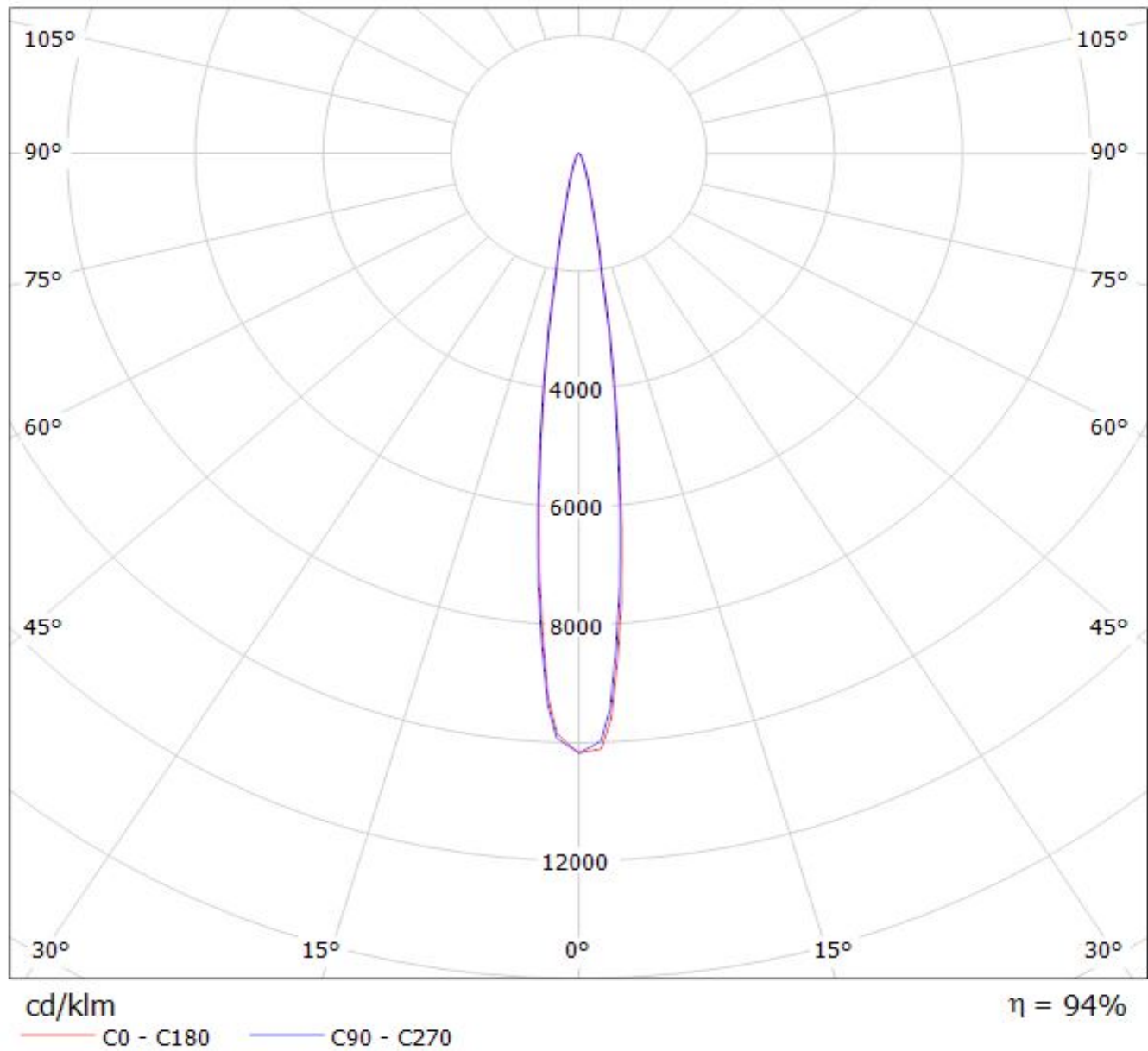

NOTE: The typical divergence will be changed by different color, chip size and chip position tolerance. The typical total divergence is the full angle measured where the luminous intensity is half of the peak value.