



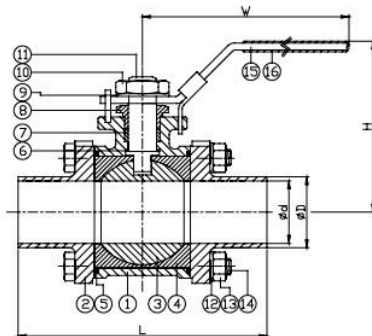

ENGLISH

Datesheet

3-PC Clean BALL VALVE

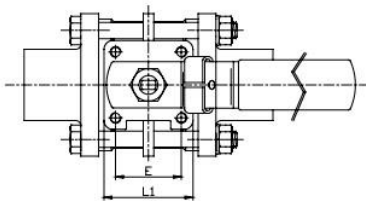

Features

- Tube end, 1/2"~2" (DN15~DN50)
- Body W.P. : 1000 WOG (PN63)
- Tube End W.P. : 200 WOG
- W.T. : -20°C~200°C (-4°F~392°F)
- Investment casting
- Blow-out proof stem
- Cavity filled seats
- Locking device
- ISO 5211 Mounting pad
- Applications : Pharmaceutical, Bio-Tech, Semiconductor, Vacuum, Drinking Water

ITEM	PARTS	MATERIAL
1	BODY	AISI 316
2	CAP	
3	BALL	
4	SEAT	PTFE
5	GASKET	
6	THRUST WASHER	
7	PACKING	AISI 304
8	GLAND NUT	
9	STEM WASHER	
10	STEM NUT	AISI 316
11	STEM	
12	WASHER	
13	NUT	AISI 304
14	BOLT	
15	HANDLE	
16	PLASTIC COVER	PLASTIC

RS Code	DN	d	D	L	L1	H	W	E	ISO 5211
918-6352	15	15	18.2	70	37	65	140	25.5	F03
918-6361	20	20	23.2	85	37	68	140	25.5	F03
918-6364	25	25	28.2	95	42	71	140	29.7	F04
918-6368	32	32	35.2	110	42	71	140	29.7	F04
918-6377	40	38	41.2	120	50	86	195	35.4	F05
918-6370	50	50	53.2	142	50	93	195	35.4	F05

unit:mm

RS Code	NPS	d	D	L	L1	H	W	E	ISO 5211
918-6352	1/2"	0.59	0.72	2.76	1.46	2.56	5.51	1	F03
918-6361	3/4"	0.79	0.91	3.35	1.46	2.68	5.51	1	F03
918-6364	1"	0.98	1.11	3.74	1.65	2.8	5.51	1.17	F04
918-6368	1-1/4"	1.26	1.39	4.33	1.65	2.8	5.51	1.17	F04
918-6377	1-1/2"	1.5	1.62	4.72	1.97	3.39	7.68	1.39	F05
918-6370	2"	1.97	2.09	5.59	1.97	3.66	7.68	1.39	F05

unit:in

01/04/2016