

### Features

- Strong and durable nylon base and zinc plated steel threaded rod
- Integrated hex nut in threaded rod to adjust height
- 20 degrees of articulation

## **RS PRO Adjustable Levelling Foot, Nylon Base, 60mm Diameter, M10x125mm Zinc Plated Steel Thread**

RS Stock No.: 0285761



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.


## Product Description

A glass-reinforced nylon base and zinc plated steel threaded rod. Height adjustment is achieved by an integrated hex nut in the threaded rod. An industry standard 15mm ball and socket provides 20° of articulation from perpendicular. The glass reinforced plastic base is tough and lightweight, while the zinc plated rod offers sufficient corrosion resistance for most indoor applications.

## General Specifications

|                    |                                                                                                                      |
|--------------------|----------------------------------------------------------------------------------------------------------------------|
| <b>Diameter</b>    | 60mm                                                                                                                 |
| <b>Thread</b>      | M10x125mm                                                                                                            |
| <b>Material</b>    | Nylon and zinc plated steel                                                                                          |
| <b>Colour</b>      | Black                                                                                                                |
| <b>Application</b> | Various types of furniture, processing and packaging machinery and equipment, lathes, milling machines and conveyors |

|                      |       |
|----------------------|-------|
| <b>A</b>             | 60    |
| <b>B</b>             | 29    |
| <b>C</b>             | 18    |
| <b>Thread size</b>   | M10   |
| <b>Thread length</b> | 125   |
| <b>Maximum load</b>  | 470kg |

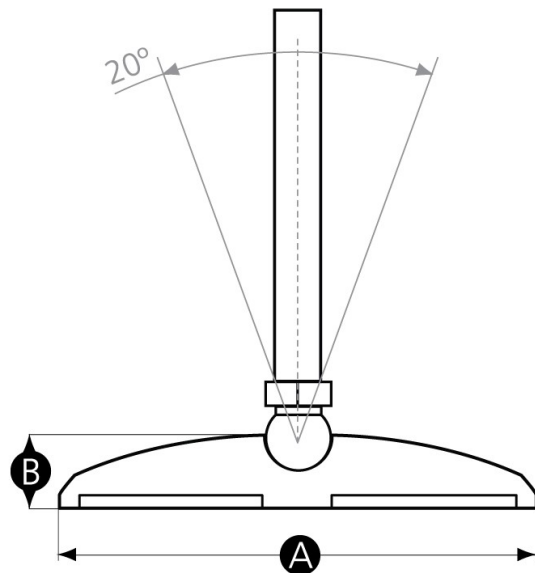

| Stock No. | Brand  | Product Name          | Diameter | Thread size |
|-----------|--------|-----------------------|----------|-------------|
| 0285750   | RS PRO | Nylon Adjustable foot | 40mm     | M8x25mm     |
| 0285751   | RS PRO | Nylon Adjustable foot | 40mm     | M8x40mm     |
| 0285752   | RS PRO | Nylon Adjustable foot | 50mm     | M8x40mm     |
| 0285754   | RS PRO | Nylon Adjustable foot | 50mm     | M8x60mm     |
| 0285755   | RS PRO | Nylon Adjustable foot | 50mm     | M8x80mm     |
| 0285757   | RS PRO | Nylon Adjustable foot | 50mm     | M10x45mm    |
| 0285758   | RS PRO | Nylon Adjustable foot | 50mm     | M10x70mm    |
| 0285760   | RS PRO | Nylon Adjustable foot | 50mm     | M10x90mm    |
| 0285761   | RS PRO | Nylon Adjustable foot | 60mm     | M10x125mm   |
| 0285763   | RS PRO | Nylon Adjustable foot | 60mm     | M10x45mm    |
| 0285764   | RS PRO | Nylon Adjustable foot | 60mm     | M10x70mm    |
| 0285766   | RS PRO | Nylon Adjustable foot | 60mm     | M12x66mm    |
| 0285767   | RS PRO | Nylon Adjustable foot | 60mm     | M12x80mm    |
| 0285768   | RS PRO | Nylon Adjustable foot | 60mm     | M12x100mm   |
| 0285770   | RS PRO | Nylon Adjustable foot | 60mm     | M12x125mm   |
| 0285772   | RS PRO | Nylon Adjustable foot | 60mm     | M12x150mm   |
| 0285773   | RS PRO | Nylon Adjustable foot | 80mm     | M12x66mm    |
| 0285774   | RS PRO | Nylon Adjustable foot | 80mm     | M12x100mm   |
| 0285776   | RS PRO | Nylon Adjustable foot | 80mm     | M16x66mm    |
| 0285777   | RS PRO | Nylon Adjustable foot | 80mm     | M16x100mm   |
| 0285779   | RS PRO | Nylon Adjustable foot | 80mm     | M16x150mm   |
| 0285780   | RS PRO | Nylon Adjustable foot | 80mm     | M20x100mm   |
| 0285782   | RS PRO | Nylon Adjustable foot | 80mm     | M20x150mm   |
| 0285783   | RS PRO | Nylon Adjustable foot | 100mm    | M16x66mm    |
| 0285785   | RS PRO | Nylon Adjustable foot | 100mm    | M16x150mm   |
| 0285786   | RS PRO | Nylon Adjustable foot | 120mm    | M20x150mm   |