
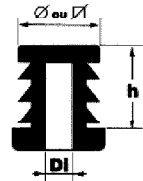
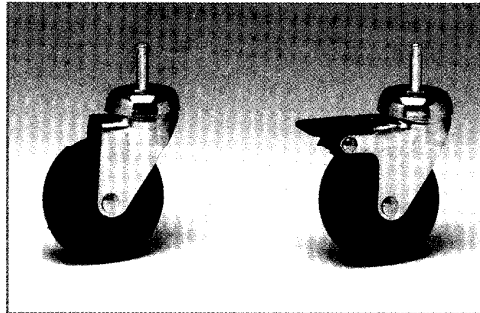


# Castors for collectivity equipment

## UNIROLL with swivel top plate and stem

30  
60  
daN

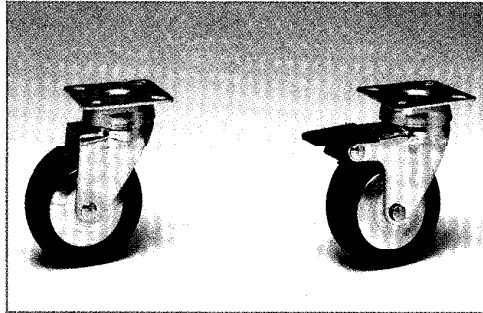

### FORK

Swivel bracket of pressed steel. Swivelling on double ball race. Top plate or stem fitting which can be equipped with a socket for rounded or squared tube. Bright zinc protection.




### BRAKE

Simple trailing brake system: wheel locking. Black polypropylene copolymer metal.

### WHEEL

PLASTEX: Non marking grey thermoplastic solid rubber tyre stuck onto the polypropylene copolymer rim. Plain bore. Without thread guards (except for top plate castors in D.75 and 100 mm).

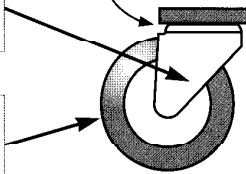

### APPLICATIONS

Light equipment for collectivities. Display units. Light furniture.

Icon 1	Icon 2	Icon 3	Icon 4	Icon 5	Icon 6	Icon 7	Icon 8	TYPE	Icon 9	REF.	CODE	Icon 10	EAN13
--------	--------	--------	--------	--------	--------	--------	--------	------	--------	------	------	---------	-------

### UNIROLL with swivel top plate

50	18	71	22	41x41	30x30	5	30	Icon 1	Icon 2	0,140	1953 S	1 953 0000	12	339680 841020 9
								Icon 1	Icon 2	0,155	1953 SAF	1 953 0010	12	339680 841025 5
75	22	102	26	60x60	40x40	6	50	Icon 1	Icon 2	0,305	1954 SPF	1 954 0000	4	339680 701954 1
								Icon 1	Icon 2	0,340	1954 SPFAF	1 954 0010	4	339680 701955 8
100	22	128	28	60x60	40x40	6	60	Icon 1	Icon 2	0,395	1955 SPF	1 955 0000	4	339680 841040 8
								Icon 1	Icon 2	0,430	1955 SPFAF	1 955 0010	4	339680 841045 3

Icon 1	Icon 2	Icon 3	Icon 4	Icon 5	Icon 6	Icon 7	TYPE	Icon 8	REF.	CODE	Icon 9	EAN13
--------	--------	--------	--------	--------	--------	--------	------	--------	------	------	--------	-------

### UNIROLL with stem for sockets with rounded or squared tubes

50	18	69	22	28	8	50	Icon 1	Icon 2	0,140	1973 S	1 973 1100	12	339680 842020 9
							Icon 1	Icon 2	0,150	1973 SAF	1 973 1110	12	339680 842025 4
75	22	100	26	28	8	60	Icon 1	Icon 2	0,250	1974 S	1 974 1100	4	339680 842030 8
							Icon 1	Icon 2	0,275	1974 SAF	1 974 1110	4	339680 842035 3

Icon 1	h	Di	REF.	CODE	EAN13 Skin
--------	---	----	------	------	------------

### rounded socket for rounded tube

12	24	8	DPR 12-T8	12 0801	339680 990030 4
14	24	8	DPR 14-T8	14 0801	339680 990031 1
16	25	8	DPR 16-T8	16 0801	339680 990032 8
18	25	8	DPR 18-T8	18 0801	339680 990033 5
20	25	8	DPR 20-T8	20 0801	339680 990034 2
23	25	8	DPR 23-T8	23 0801	339680 990035 9
24	25	8	DPR 26-T8	26 0801	339680 990036 6

Icon 1	h	Di	REF.	CODE	EAN13 Skin
--------	---	----	------	------	------------

### squared socket for squared tube

13x13	24	8	DPC 13x13 T8	13 0800	339680 990130 1
18x18	25	8	DPC 18x18 T8	18 0800	339680 990131 8
23x23	25	8	DPC 23x23 T8	23 0800	339680 990132 5