



Terminals & Splices > Terminal Housings, Insulation Sleeves & Blocks > Crimp Terminal Housings



Terminal Type: **Tab**
Connector & Housing Type: **Tab Housing**
Number of Positions: **8**
Terminal Orientation: **Straight**
Primary Product Color: **Gray**

Features

Product Type Features

Sealable	No
Connector & Housing Type	Tab Housing

Configuration Features

Number of Positions	8
---------------------	---

Body Features

Primary Product Color	Gray
-----------------------	------

Contact Features

Terminal Type	Tab
Terminal Orientation	Straight
Contact Mating Retention	With

Mechanical Attachment

Mating Retention Type	Latch
Mating Alignment	With



Connector Mounting Type	Cable Mount (Free-Hanging)
-------------------------	----------------------------

Housing Features

Housing Material	PBT
Centerline (Pitch)	6 mm[.236 in]

Dimensions

Product Length	35 mm[1.38 in]
----------------	----------------

Usage Conditions

Operating Temperature Range	-40 – 105 °C[-40 – 221 °F]
-----------------------------	----------------------------

Packaging Features

Packaging Quantity	800
Packaging Method	Carton

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

TE Part # 5-144835-3
HOUSING TAB 5MM 3 P GREEN

TE Part # 6-316441-6
FF 187 PLUG 8P ASSY LIGHT GRAY

TE Part # CAT-T4827-CH8172
Timer Connector Housing

TE Part # 964473-1
FF 110 TAB HSG 10P PBT BLACK

TE Part # 338696-1
FASTIN FASTON (FF) HOUSING TAB

Also in the Series | FASTIN-FASTON 110

Automotive Housings(6)


Automotive Terminals(5)

Crimp Terminal Housings(34)

Insertion & Extraction Tools(3)

Quick Disconnects(78)


Customers Also Bought

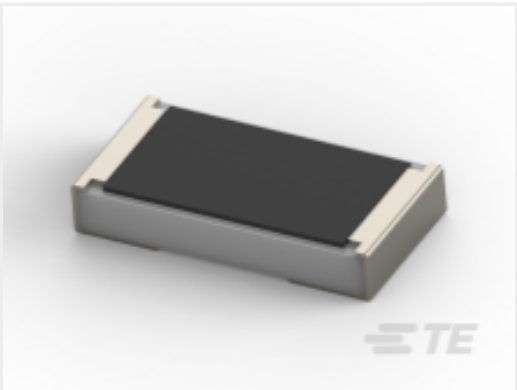


TE Part #2176468-1
TLRP 2010 1.0W R010 1% 75PPM 4K RL




TE Part #5747842-2
25 MSFL PLUG RA 318 (FM,BL)

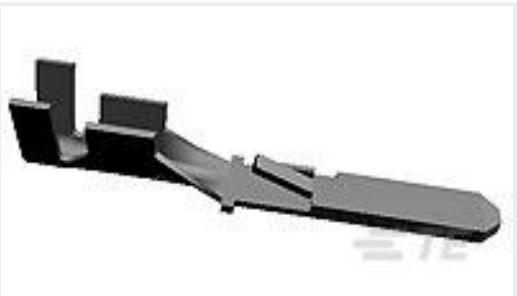

TE Part #160743-4
110 FASTIN FASTON,TAB,20-16 AWG,
PTBR

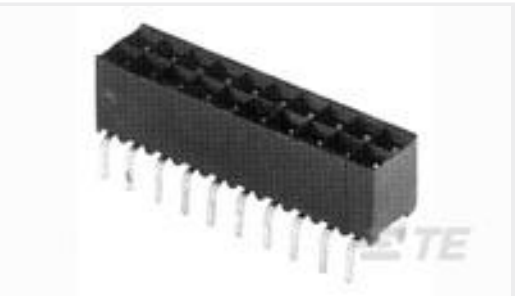

TE Part #1-829264-0
2X10P HV100 REC.CON.B/TE,6.2MM,
NO KINK

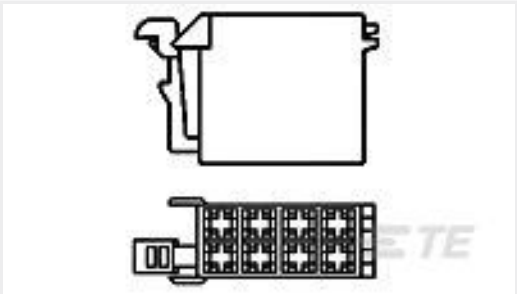

TE Part #962189-1
8P JUNIOR-TIMER GH




TE Part #5-146130-4
10 MODII HDR DRST SFMNT B/A LF




TE Part #3-1614884-4
CPF 0805 51R 0.1% 25PPM 1K RL



TE Part #925595-1
MIN.SPRING RECEPT.

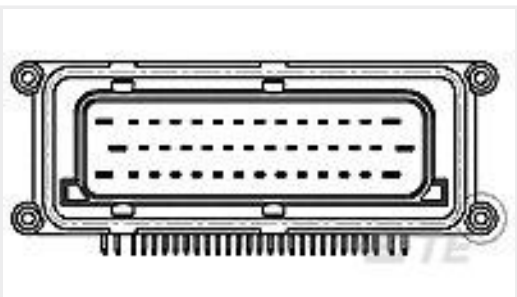

TE Part #1-967280-1
MESSERLEISTE MIX42P

 

TE Part #K1070513
Schlagschalter (Hauptantr) 06-63-410

Documents

Product Drawings

FF 110 PLUG HSG 8P.

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_106455-3_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_106455-3_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_106455-3_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



White Paper: Nylon Discoloration

English

Product Specifications

Application Specification

English