


Features

- Made from tough, hard-wearing GRP with a grit surface for excellent slip resistance.
- The paint pigment used in the product complies with ASTM E1645-01, ensuring the product is safe and reduces the risk of lead exposure to meet regulatory standards.
- A high-quality flooring option that offers a credible alternative to steel mesh grating
- The quartz crystal-bonded top surface provides extreme durability and high slip resistance.
- Perfect for high-traffic areas or demanding, corrosive environments.
- Half the weight of steel solutions, making it easy to install with no ongoing maintenance.
- Manufactured from Type O, Orthophthalic Polyester resin, ensuring high performance and durability.
- Strong bi-directional properties allow the product to be used in various applications, making it more versatile.
- Slip test to EN 16165:2021 Annex B.
- Fire tested to EN 13501-1:2018.

RS PRO GRP Grating - Yellow 2000mm x 1000mm x 25mm

RS Stock No.: 0712645

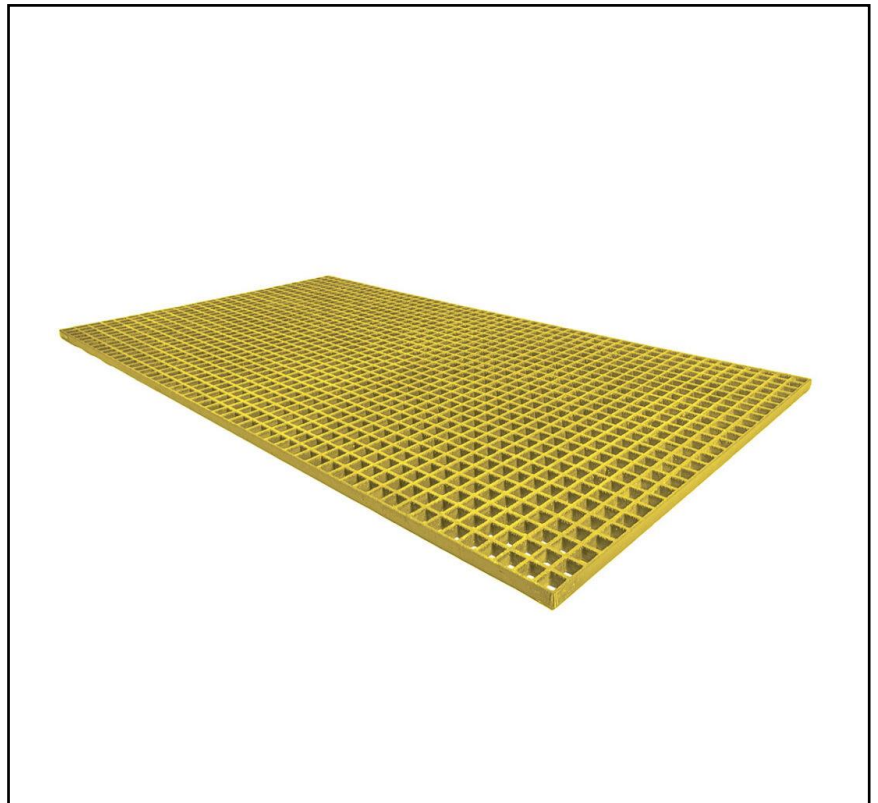

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

- Made from tough, hard-wearing GRP with a grit surface for excellent slip resistance.
- The paint pigment used in the product complies with ASTM E1645-01, ensuring the product is safe and reduces the risk of lead exposure to meet regulatory standards.
- A high-quality flooring option that offers a credible alternative to steel mesh grating.
- The quartz crystal-bonded top surface provides extreme durability and high slip resistance.
- Perfect for high-traffic areas or demanding, corrosive environments.
- Half the weight of steel solutions, making it easy to install with no ongoing maintenance.
- Manufactured from Type O, Orthophthalic Polyester resin, ensuring high performance and durability.
- Strong bi-directional properties allow the product to be used in various applications, making it more versatile.
- Slip test to EN 16165:2021 Annex B.
- Fire tested to EN 13501-1:2018.

General Specifications

Size	2000 mm x 1000 mm x 25 mm
Colour	Yellow
Weight (kg)	26
Material	GRP with quartz sand bonded on top (with resin)
Surface Finish	Quartz grit
Min. Operating Temperature	-50°C
Max. Operating Temperature	+60°C

Approvals

Slip test to	EN 16165:2021 Annex B
Fire tested to	EN 13501-1:2018

Similar Products

Stock No.	Brand	Product Name	Size	Colour	Weight (kg)
0712639	RS PRO	GRP Grating	2000 mm x 1000 mm x 25 mm	Green	26
0712640	RS PRO	GRP Grating	2000 mm x 1000 mm x 38 mm	Green	38
0712641	RS PRO	GRP Grating	2000 mm x 1000 mm x 50 mm	Green	42
0712642	RS PRO	GRP Grating	2000 mm x 1000 mm x 25 mm	Grey	26
0712643	RS PRO	GRP Grating	2000 mm x 1000 mm x 38 mm	Grey	38
0712644	RS PRO	GRP Grating	2000 mm x 1000 mm x 50 mm	Grey	42
0712647	RS PRO	GRP Grating	2000 mm x 1000 mm x 38 mm	Yellow	38
0712648	RS PRO	GRP Grating	2000 mm x 1000 mm x 50 mm	Yellow	42