


Manual Unlock PV Connector

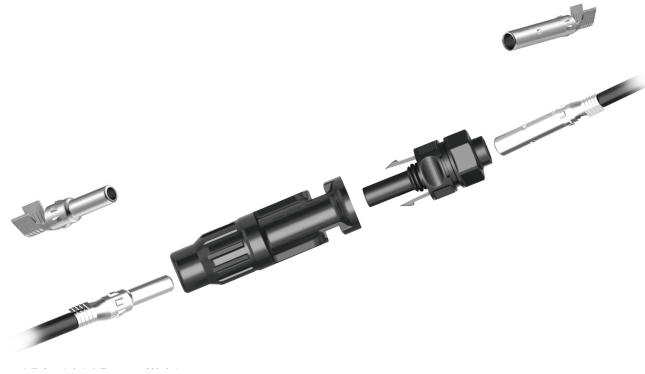


Specification


Applicable Terminal	10 mm ²
Rated Current	50 A
Cable Size Range	8 AWG
Rated Voltage	1.5 kVDC
Contact Resistance	300 mOhm
Degree of Protection	IP68
Working Temperature	-40 ~ 105°C
Class of Pollution	Grade III
Flammability	UL94-V0

Drawings



Device side Socket

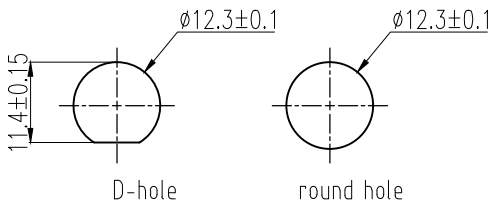



mounting hole size on panel

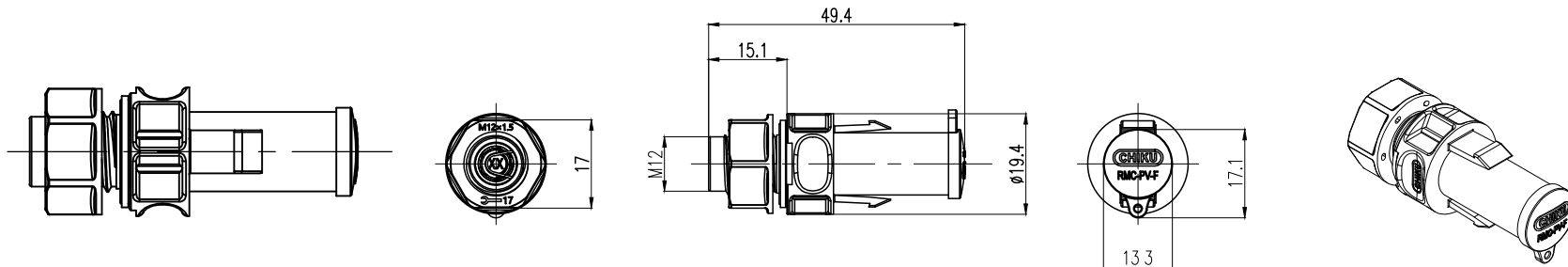



Cable side Plug

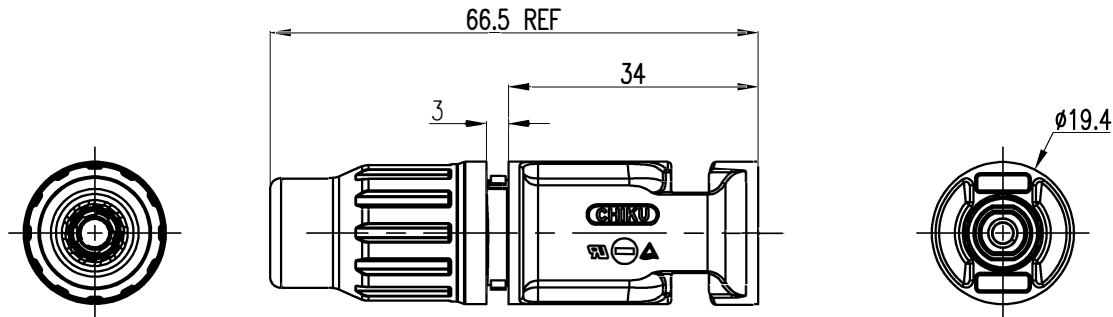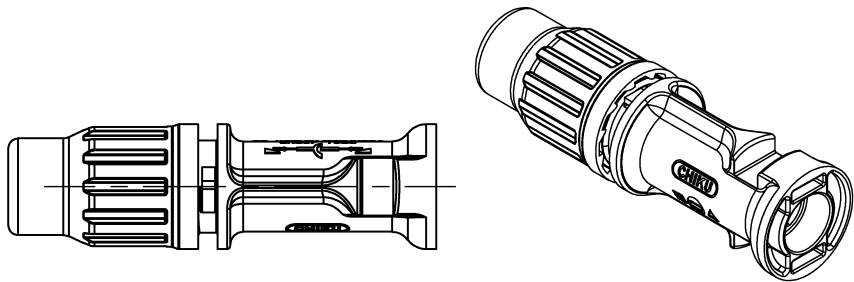

Terminal Socket

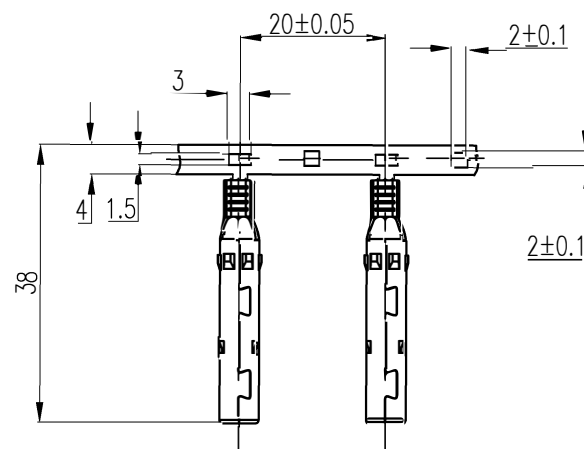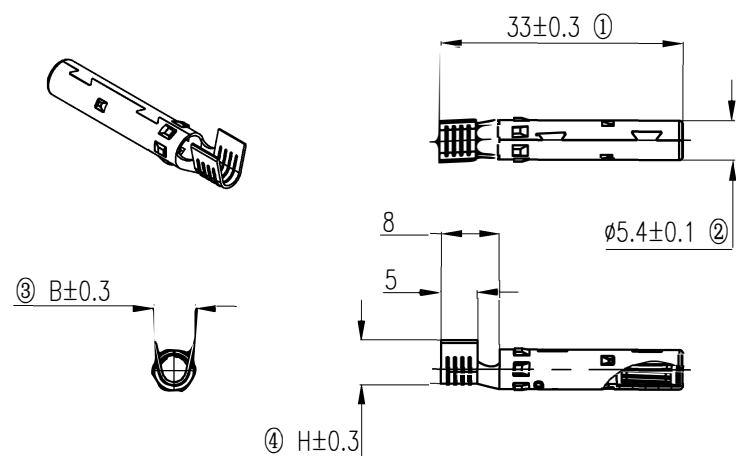

Terminal Plug

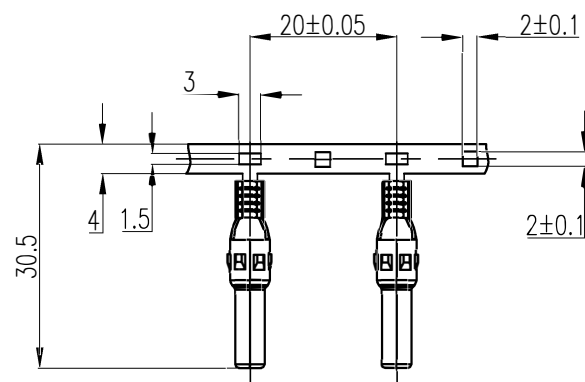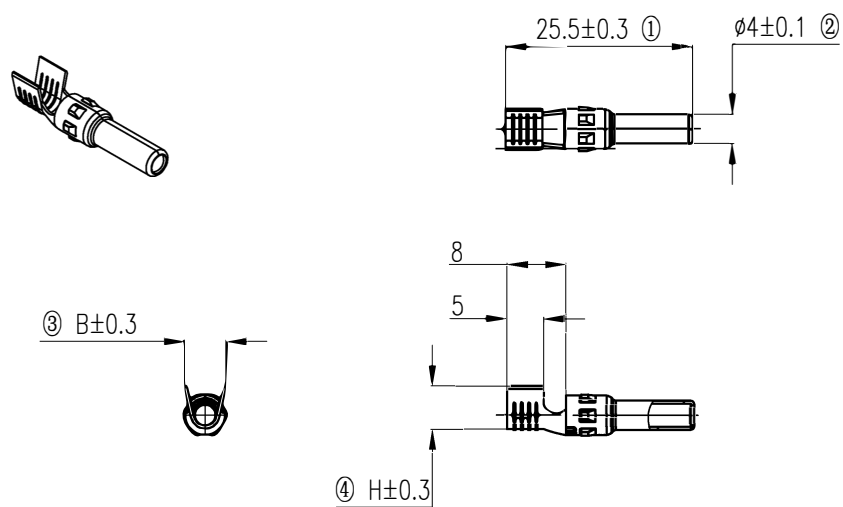

Art. Nr.
RND 205-01576