



CROW-FOOT spanner



540

Product no. **02200025**
GTIN **4018754141081**
Model **540 25**

Label. 3/8 " CROW-FOOT spanner Size 25mm L.47mm

Properties. • Chrome Alloy Steel, chrome-plated

Technical drawing.

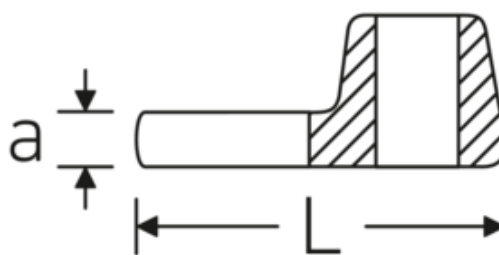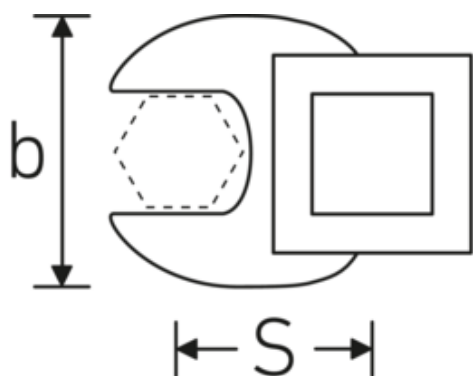

Technical attributes.

a	8 mm
Square drive inner (inch)	3/8 "
Width mm (b)	45 mm
Length mm (L)	47 mm
S	26,4 mm
Size [mm]	25 mm

Logistics data.

Depth mm (IFS)	48
Width mm (IFS)	45
Height mm (IFS)	18
WEEE/ElektroG	nicht ear-pflichtig
Length (packaged, mm)	70
Width (packaged, mm)	60
Height (packaging, mm)	19

Volume (packaged, dm3)	0.0798 dm3
Product no.	02200025
Weight (gross, kg)	0,080
Weight PAP (kg)	0,000
Weight PVC (kg)	0,004
GTIN	4018754141081
Country of origin AWR	GERMANY
Region of origin	Nordrhein-Westfalen
Customs tariff no.	82042000
Packing standard	1
Weight (g)	75 g

Variants.

Product no.	Model No. (ERP)	Description	GTIN
01200008	540 8	1/4 " Crow-foot spanner Size 8mm L.25.5mm	4018754149117
01200009	540 9	1/4 " Crow-foot spanner Size 9mm L.25.5mm	4018754149124
01200010	540 10	1/4 " CROW-FOOT spanner Size 10mm L.25.5mm	4018754149131
02200011	540 11	3/8 " CROW-FOOT spanner Size 11mm L.32mm	4018754149414
02200012	540 12	3/8 " CROW-FOOT spanner Size 12mm L.34.3mm	4018754003495
02200013	540 13	3/8 " CROW-FOOT spanner Size 13mm L.34.3mm	4018754003501
02200014	540 14	3/8 " CROW-FOOT spanner Size 14mm L.37.7mm	4018754003518
02200015	540 15	3/8 " CROW-FOOT spanner Size 15mm L.37.7mm	4018754003525
02200016	540 16	3/8 " CROW-FOOT spanner Size 16mm L.37.7mm	4018754003532
02200017	540 17	3/8 " CROW-FOOT spanner Size 17mm L.42.5mm	4018754003549
02200018	540 18	3/8 " CROW-FOOT spanner Size 18mm L.42.5mm	4018754003556
02200019	540 19	3/8 " CROW-FOOT spanner Size 19mm L.42.5mm	4018754003563
02200020	540 20	3/8 " CROW-FOOT spanner Size 20mm L.42.4mm	4018754141067
02200021	540 21	3/8 " CROW-FOOT spanner Size 21mm L.44.5mm	4018754003570
02200022	540 22	3/8 " CROW-FOOT spanner Size 22mm L.44.5mm	4018754003587
02200023	540 23	3/8 " CROW-FOOT spanner Size 23mm L.44.5mm	4018754141074
02200024	540 24	3/8 " CROW-FOOT spanner Size 24mm L.44.4mm	4018754003594
02200025	540 25	3/8 " CROW-FOOT spanner Size 25mm L.47mm	4018754141081
02200026	540 26	3/8 " CROW-FOOT spanner Size 26mm L.47mm	4018754149162
02200027	540 27	3/8 " CROW-FOOT spanner Size 27mm L.47mm	4018754149179
02200028	540 28	3/8 " CROW-FOOT spanner Size 28mm L.50mm	4018754148806
02200030	540 30	3/8 " CROW-FOOT spanner Size 30mm L.50mm	4018754149186

02200032	540 32	3/8 " CROW-FOOT spanner Size 32mm L.53mm	4018754149193
02200034	540 34	3/8 " CROW-FOOT spanner Size 34mm L.54.5mm	4018754141098
02200036	540 36	3/8 " CROW-FOOT spanner Size 36mm L.56.5mm	4018754141104
02200040	540 40	3/8 " CROW-FOOT spanner Size 40mm L.63mm	4018754141111
02200041	540 41	3/8 " CROW-FOOT spanner Size 41mm L.63mm	4018754141128
02200042	540 42	3/8 " CROW-FOOT spanner Size 42mm L.63mm	4018754141135
02200046	540 46	3/8 " CROW-FOOT spanner Size 46mm L.72mm	4018754141142
02200050	540 50	3/8 " CROW-FOOT spanner Size 50mm L.75mm	4018754141159

GTIN.



STAHLWILLE Eduard Wille GmbH

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal