


MINI PLIERS


Ega Master offers a wide range of pliers, such as Electronic mini.

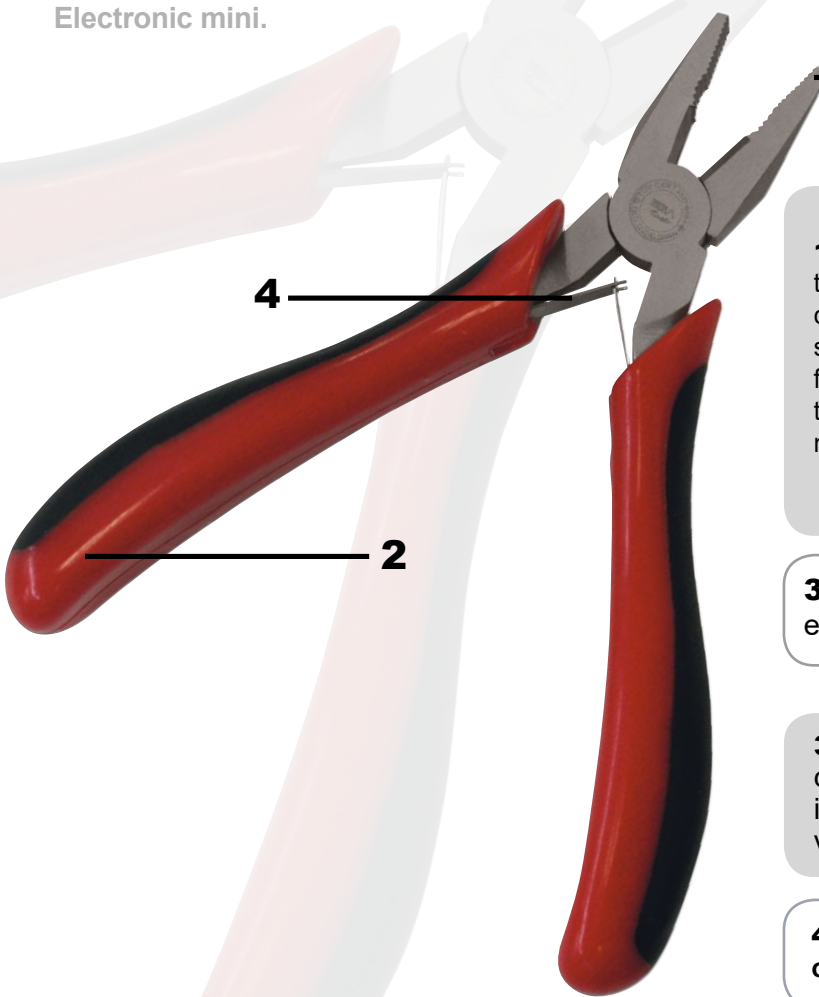

BIMAT
TITACROM®




1. These pliers are suitable for electrical applications due to their small size. They are designed for gripping, bending, cutting ... for any work that needs high precision.

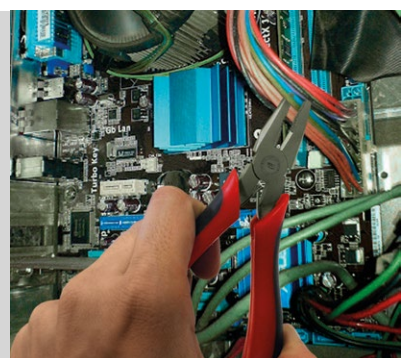

3. **BIMAT** bicomponent handles provide non-slip, ergonomic and maximum comfort grip.

3. **TITACROM®** - is a special surface treatment, more corrosion resistant than standard chrome, resistant to impact and friction (non peel off), non reflecting with very attractive finishing.


4. Double spring for a light and uniform opening.

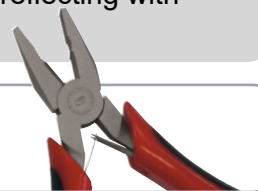

TITACROM BIMAT UNIVERSAL



ISO-DIN-9655
UNE-16544

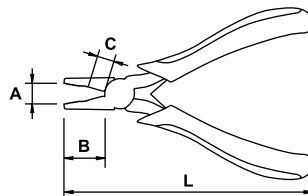

COD	←L→	A	B	C				gr		
62241	125mm	19mm	21mm	8mm	2	1,5	1	70	6	1



Soft
20Kg/mm² - 200N/mm²



Medium
75Kg/mm² - 750N/mm²



Hard
180Kg/mm² - 1800N/mm²




Piano wire
230Kg/mm² - 2300N/mm²

TITACROM BIMAT FLAT NOSE



ISO-DIN-9655
UNE-16544

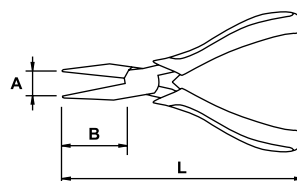


COD	L	A	B	gr.		
62242	130mm	21mm	28mm	65	6	1

TITACROM BIMAT ROUND NOSE



ISO-DIN-9655
UNE-16544

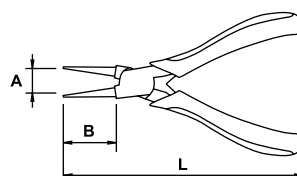


COD	L	A	B	gr.		
62243	130mm	40mm	25mm	60	6	1

TITACROM BIMAT LONG NOSE



ISO-DIN-9655
UNE-16544

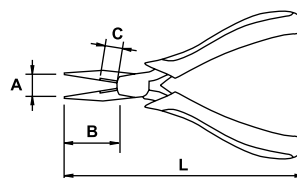


COD	L	A	B	C					gr.		
62244	130mm	42mm	28mm	8mm	2	1,5	1		65	6	1

TITACROM BIMAT BENT NOSE PLIERS



ISO-DIN-9655
UNE-16544

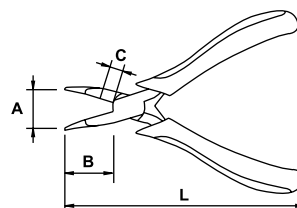

COD	L	A	B	C	gr.		
62245	130mm	44mm	26mm	9mm	65	6	1



Soft
20Kg/mm² - 200N/mm²



Medium
75Kg/mm² - 750N/mm²



Hard
180Kg/mm² - 1800N/mm²




Piano wire
230Kg/mm² - 2300N/mm²

TITACROM BIMAT LONG NEEDLE NOSE



ISO-DIN-9655
UNE-16544

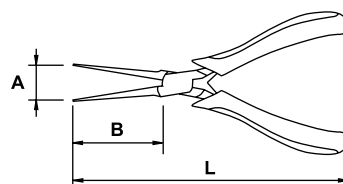


COD	L	A	B	gr.		
62246	150mm	65mm	48mm	65	6	1

TITACROM BIMAT DIAGONAL CUTTING PLIERS



ISO-DIN-9654
UNE-16543

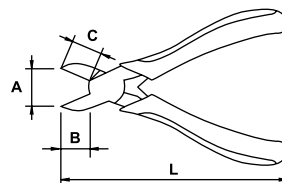


COD	L	A	B	C				gr.		
62247	115mm	13mm	15mm	13mm	1,6	1,2	0,5	60	6	1

TITACROM BIMAT DIAGONAL CUTTING TRIANGULAR



ISO-DIN-9654
UNE-16543

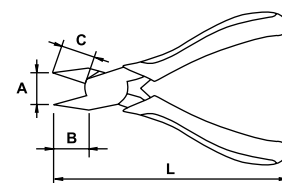


COD	L	A	B	C				gr.		
62248	115mm	25mm	14mm	13mm	1,6	1,2	0,5	60	6	1


TITACROM BIMAT END CUTTING NIPPER



ISO-DIN-9654
UNE-16543

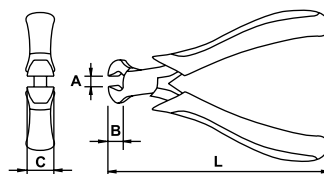

COD	L	A	B	C				gr.		
62249	110mm	19mm	7,5mm	17mm	2	1	0,5	60	6	1

 

Soft
20Kg/mm² - 200N/mm²



Medium
75Kg/mm² - 750N/mm²



Hard
180Kg/mm² - 1800N/mm²



Piano wire
230Kg/mm² - 2300N/mm²

DISPLAYS


BMAT



COD	UN.		← L →
62265	6	62241	125mm
	3	62242	
		62243	
		62244	
		62245	
	6	62246	150mm
		62247	115mm
	3	62248	
		62249	
	TITACROM®		

KITS

BMAT

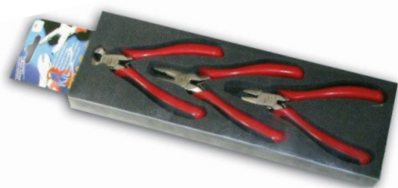

COD	UN.		← L →
69434	1	62249	110mm
		62241	125mm
		62247	115mm
TITACROM®			



T

COD	UN.		← L →
69433	1	62244	125mm
		62245	
		62246	150mm
		62247	115mm
		62249	110mm
		66846	50x2
		66850	PH-00
		69530	-
TITACROM®			

TECHNICAL SPECIFICATIONS

MATERIAL	Body	Acero especial
	Handles	PVC+TPR
HARDNESS	Cutting edge	55-60 HRC
FINISHING	TITACROM®	