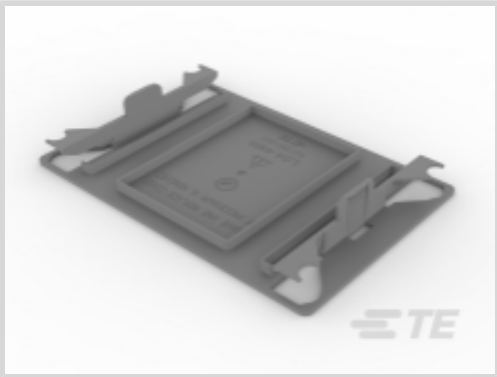




Connectors > Connector Accessories > Connector Caps & Covers



Connector Cover Type: **Dust Cover**

Primary Product Material: **PC + ABS**

Operating Temperature (Max): **100 °C [212 °F]**

Operating Temperature Range: **-25 – 100 °C [-13 – 212 °F]**

Features

Product Type Features

Connector Cover Type	Dust Cover
----------------------	------------

Body Features

Primary Product Material	PC + ABS
--------------------------	----------

Usage Conditions

Operating Temperature (Max)	100 °C[212 °F]
Operating Temperature Range	-25 – 100 °C[-13 – 212 °F]

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Method	Box & Tray
------------------	------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC















Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

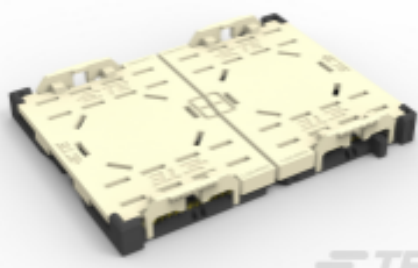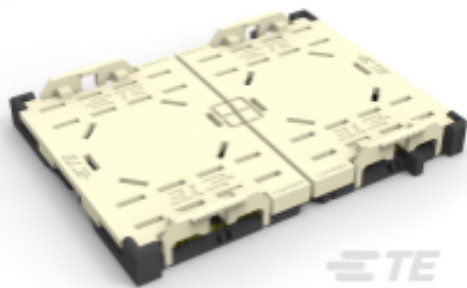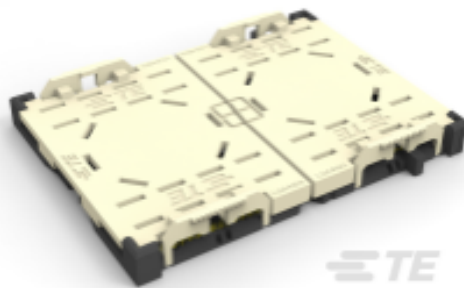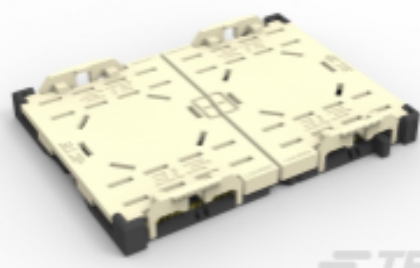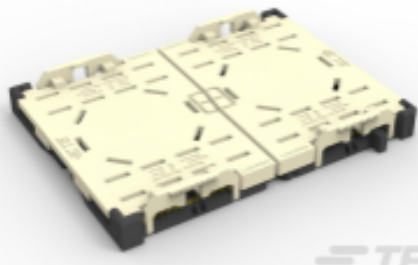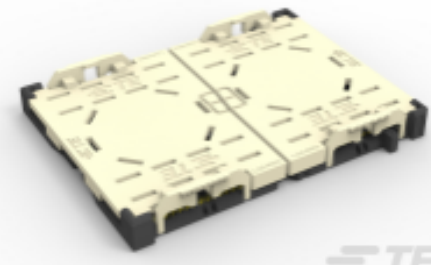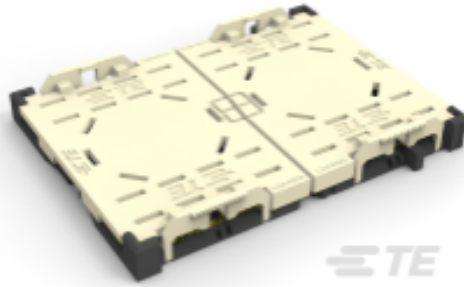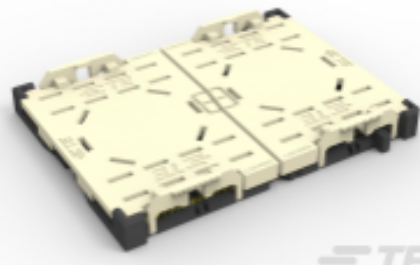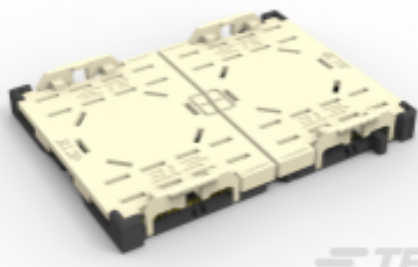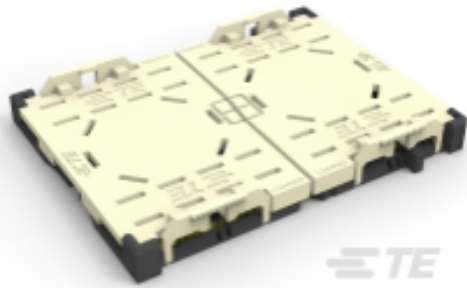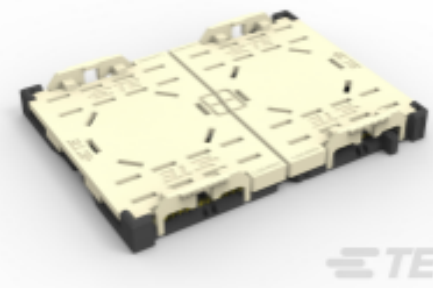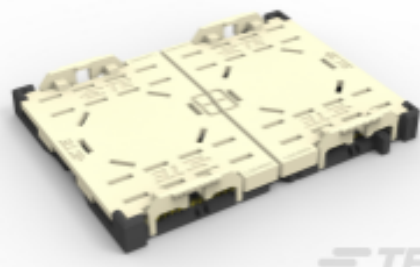Compatible Parts


 TE Part # 1-2324271-1 RIGHT SEGMENT LGA4189-4 SOCKETP4 FOR ODM	 TE Part # 1-2324271-6 LEFT SEGMENT LGA4189-5 SOCKET-P5 FOR ODM	 TE Part # 1-2324271-8 LEFT SEGMENT LGA4189-5 SOCKET-P5 FOR ODM	 TE Part # 1-2324271-3 RIGHT SEGMENT LGA4189-4 SOCKETP4 FOR ODM
 TE Part # 1-2332283-2 LGA4189-4 SOCKET P4 KIT FOR ODM (15U AU)	 TE Part # 1-2332283-4 LGA4189-5 SOCKET P5 KIT FOR ODM (15U AU)	 TE Part # 1-2324271-5 RIGHT SEGMENT LGA4189-5 SOCKETP5 FOR ODM	 TE Part # 1-2332283-3 LGA4189-5 SOCKET P5 KIT FOR ODM (30U AU)
 TE Part # 1-2332283-1 LGA4189-4 SOCKET P4 KIT FOR ODM (30U AU)	 TE Part # 1-2324271-7 RIGHT SEGMENT LGA4189-5 SOCKETP5 FOR ODM	 TE Part # 1-2324271-4 LEFT SEGMENT LGA4189-4 SOCKET-P4 FOR ODM	 TE Part # 1-2324271-2 LEFT SEGMENT LGA4189-4 SOCKET-P4 FOR ODM

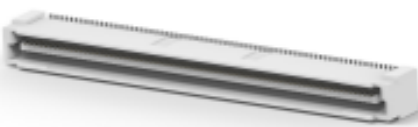Customers Also Bought





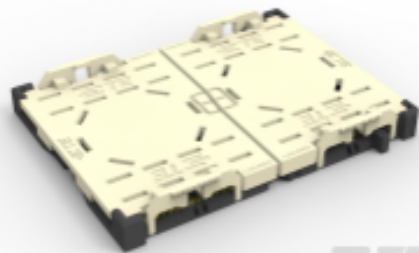
TE Part #CAT-313-PCB140
Free Height Plug Connector: Board-Board, Vertical, 140, 0.8mm




TE Part #1-2324271-2
LEFT SEGMENT LGA4189-4 SOCKET-P4 FOR ODM



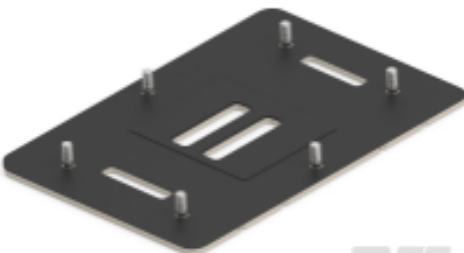TE Part #2-2351050-4
LGA4677 TFLM ASSY,W/O COVER



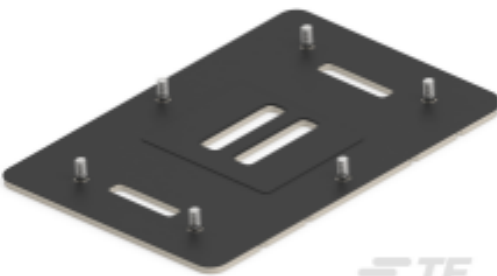
TE Part #2351051-2
LGA4677 BACKPLATE ASSY, LONG STUD



TE Part #2351051-1
LGA4677 BACKPLATE ASSY, SHORT STUD



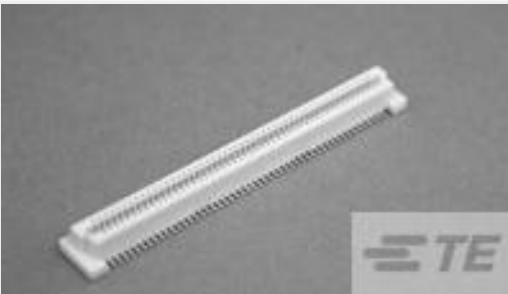
TE Part #2227728-1
zSFP+ 1x2 Cage Assy, Press-Fit



TE Part #5177985-6
0.8FH,R05H.5,140,08/Sn,TR,SC



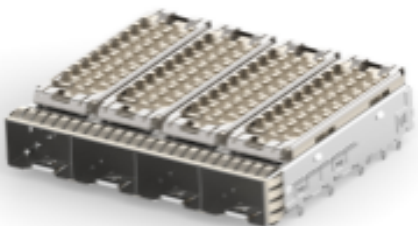TE Part #2199155-2
DDR4 DIMM 288 Pin SMT type



TE Part #2348348-1
zSFP+ 1X4 CAGE ASSEMBLY, PRESS-FIT, HS

Documents

Product Drawings

SOCKET P4/P5 DUST COVER, LGA4189

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2-2330553-1_B.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2-2330553-1_B.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2-2330553-1_B.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



LGA 4189 Socket and Hardware

English

1-1773982-5-lga_4189_flyer_cn

English

Product Specifications

Application Specification

English