

scale cover, sealable for circuit breaker 3RV2 Size S00...S3



General technical data		
Product brand name		SIRIUS
Product designation		covers
Design of the product		scale cover, sealable, for covering the current setting scale
Ambient temperature		
• during operation	°C	-20 ... +70
• during storage	°C	-50 ... +80
Installation/ mounting/ dimensions		
Mounting type		clip-on
Width	mm	17
Height	mm	16
Depth	mm	1
Certificates/ approvals		
Certificate of suitability		CE / UL / CSA / CCC

General Product Approval	Declaration of Conformity	Test Certificates	Shipping Approval
--------------------------	---------------------------	-------------------	-------------------



[Miscellaneous](#)

[Type Test Certificates/Test Report](#)

[Special Test Certificate](#)



Shipping Approval	other
-------------------	-------



[Confirmation](#)

other



Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RV2908-0P>

Cax online generator



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RV2908-0P>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RV2908-0P>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RV2908-0P&lang=en

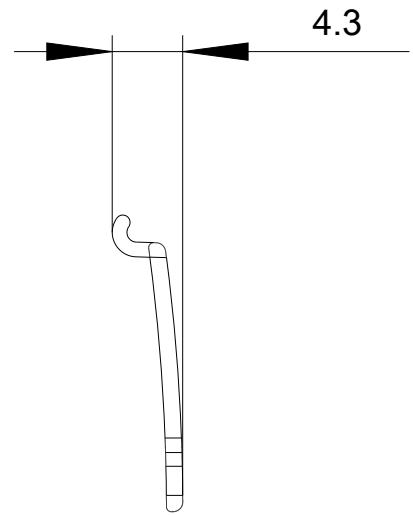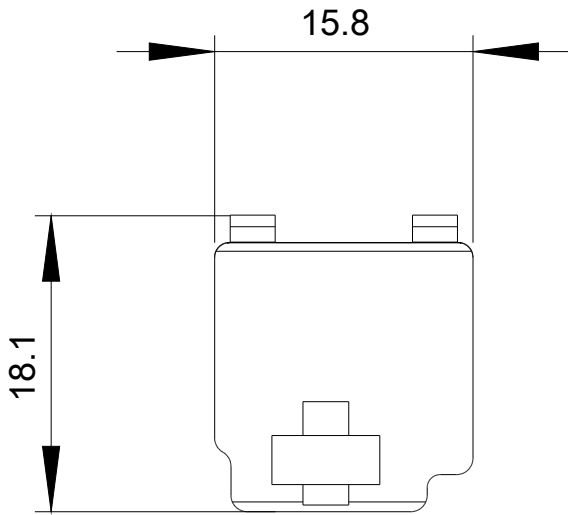

last modified:

09/23/2020