



Inside puller



Description:

- Versatile: takes 2 or 3 legs. Converts into outside puller with the legs U.306G1 + screw U.20B1 or legs U.310G2 + screw U.310-250-10.
- Comfort: self-gripping legs by return spring. The puller stays in rolling position even when not in tension.
- Safety: legs locked in position on the bearing using a knob. No risk for the puller to escape from the bearing.
- Adaptable puller accessories: hydraulic screw U.3 and slide hammer U.2.

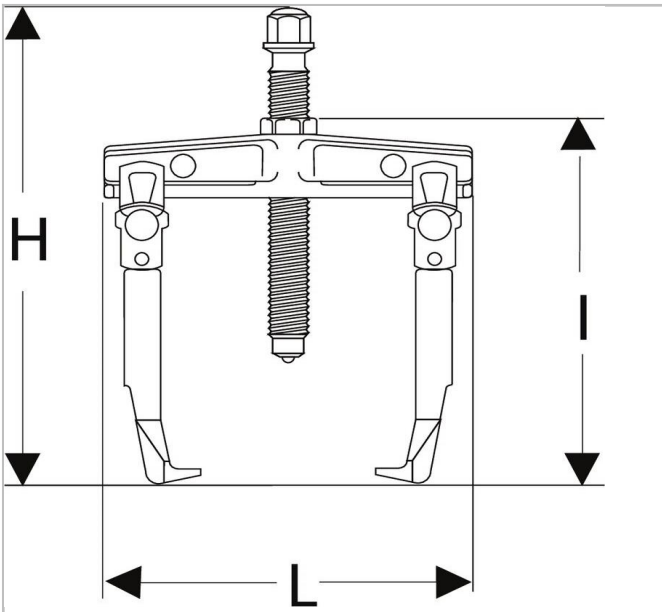

	Depth Maxi [mm]	Length L [mm]	Height H [mm]	C Min i - Ma xi [mm]	Length [mm]	Hex Size [mm]	Screw Size ["]	t ["]	Weight [Kg]	Legs_M ulti ["]	Screw Size Multi ["]	Tonnes ["]
U.310-230N	200.0	180.0	400.0	50 - 230	360.0	24.0	U.20 B1	100.0	4.1	U.310G3	24.0	10.0