


Floor marking window A4 removable

Article number	180804	Sales unit quantity	1 Pack
Colour	Yellow	Sales unit EAN	4005546726007
Packaging unit	10 pieces / 1 pack	Packing weight (gross)	817.2 G
Base EAN	4005546726007	Country of origin	GB

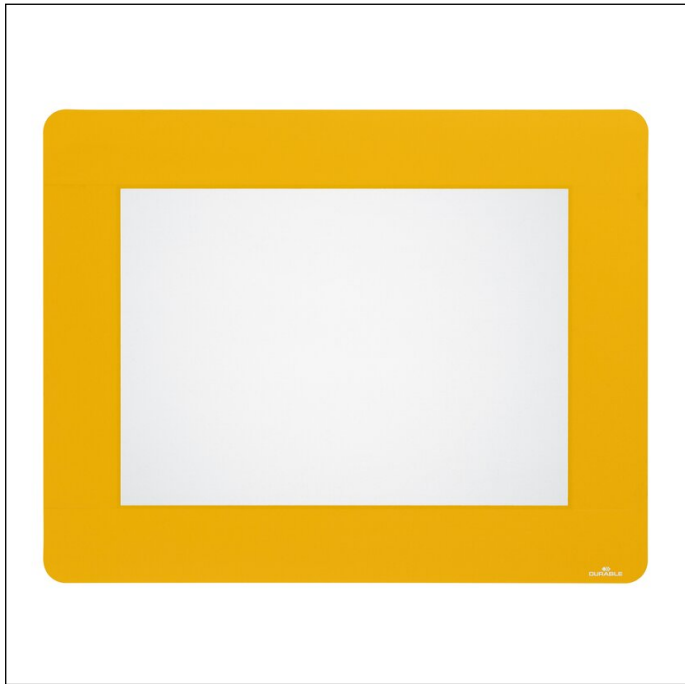

Logos and awards



Product description

- Floor marking windows for labelling with paper inserts
- For portrait and landscape formats
- Self-adhesive strips stick the window to the ground
- Easy mounting: Paper in A4 format is inserted under the clear labelling pocket, while the surrounding adhesive protects it
- Slip resistance (R Group) R9 in accordance with German workplace ordinance ASR A1.5/1,2 'Floors' per DIN 51130
- Frame colour signal yellow, similar to RAL 1003
- Window dimensions: 297 x 210 mm (W x H)

Product features

Outer width (mm)	401
Outer height (mm)	314

Floor marking window A4 removable

Outer depth / length	0.4 mm
Format / Format for	A4
Orientation Format	Portrait / landscape
Brand	DURABLE
Inner width (mm)	297
Inner height (mm)	210
Shape	A4
Self-adhesive type	Removable
Adhesive strength	Normal
Abrasion resistance	Normal
Special colour	Similar to RAL 1003 signal yellow
Application area	Walking area
Technical standard	ASR A1.5/1.2 "Floors" according to DIN 51130 Slip resistance (R group) R9