


KEMET Part Number: PME271YC5330MR30
(P272CE333M300A)

PME271Y/P272, Film, Metallized Paper, Safety, 0.033 uF, 20%, 300 VAC (Y2), 1000 VDC, 115°C, Lead Spacing = 20.3mm

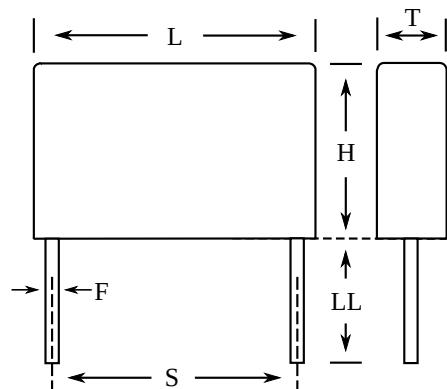

Dimensions

L	24mm MAX
H	14mm MAX
T	7.6mm MAX
S	20.3mm +/-0.4mm
LL	30mm +5mm
F	0.8mm +/-0.05mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	250

General Information

Supplier:	KEMET
Series:	PME271Y/P272
Dielectric:	Metallized Paper
Style:	Radial
Features:	EMI Safety
RoHS:	Yes
Lead:	Wire Leads
Qualifications:	ENEC, UL, cUL, CQC
Construction:	Molded
Miscellaneous:	SRF= 7 MHz

Specifications

Capacitance:	0.033 uF
Capacitance Tolerance:	20%
Voltage AC:	300 VAC (Y2)
Voltage DC:	1000 VDC
Temperature Range:	-40/+115C
Rated Temperature:	115°C
Dissipation Factor:	1.3% 1kHz
Insulation Resistance:	12 GOhms
Max dV/dt:	1000 V/us
Safety Class:	Y2