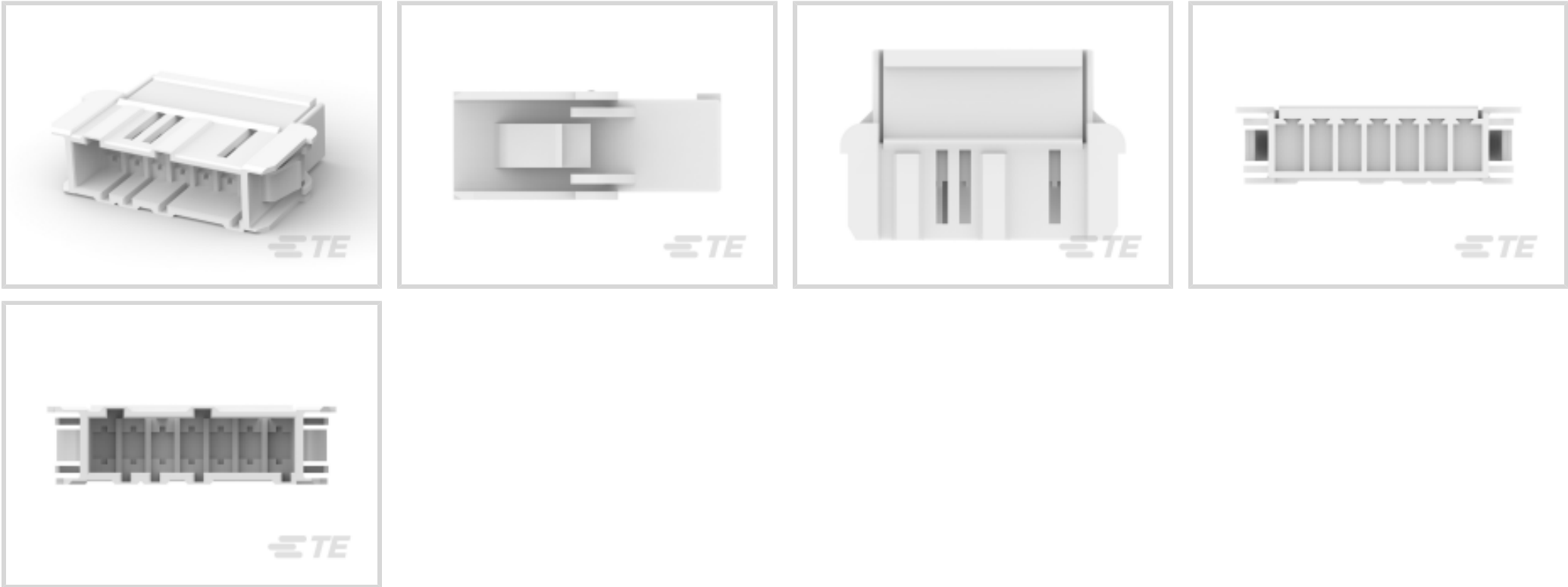




Terminals & Splices > Terminal Housings, Insulation Sleeves & Blocks > Crimp Terminal Housings



Terminal Type: **Tab**
Connector & Housing Type: **Tab Housing**
Number of Positions: **7**
Terminal Orientation: **Straight**
UL Flammability Rating: **UL 94V-2**

Features

Product Type Features

Sealable	No
Connector & Housing Type	Tab Housing

Configuration Features

Number of Positions	7
---------------------	---

Body Features

Primary Product Color	Natural
-----------------------	---------

Contact Features

Terminal Type	Tab
Terminal Orientation	Straight
Contact Mating Retention	With

Mechanical Attachment

Mating Alignment Type	Polarization
Mating Alignment	With



Connector Mounting Type	Panel Mount
-------------------------	-------------

Housing Features

Housing Material	Polyamide
Centerline (Pitch)	5 mm[.196 in]

Dimensions

Product Length	33 mm[1.7 in]
----------------	---------------

Usage Conditions

Operating Temperature Range	-40 – 105 °C[-40 – 221 °F]
-----------------------------	----------------------------

Industry Standards

UL Flammability Rating	UL 94V-2
------------------------	----------

Packaging Features

Packaging Quantity	200
--------------------	-----

Product Compliance

For compliance documentation, visit the product page on TE.com>

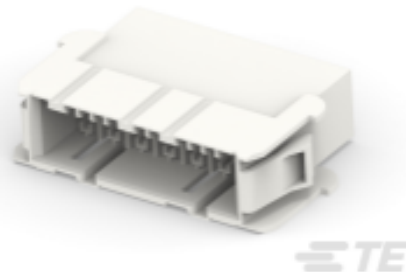
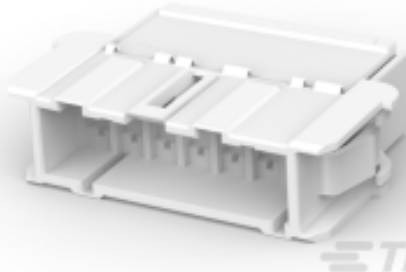
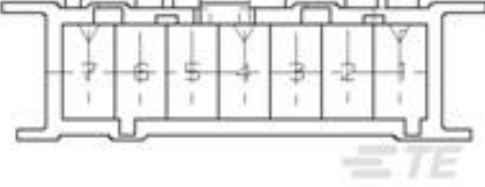
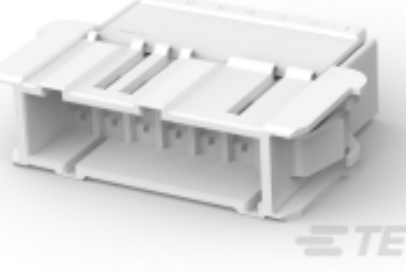
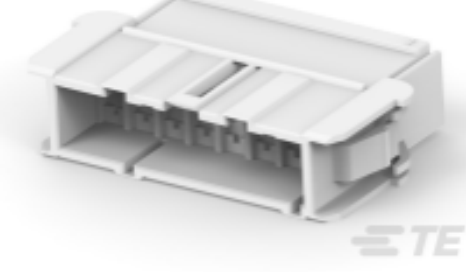
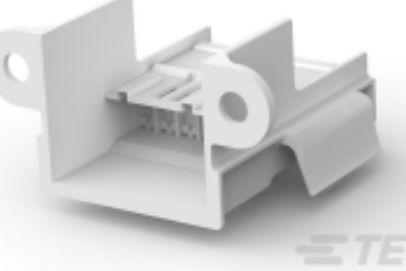
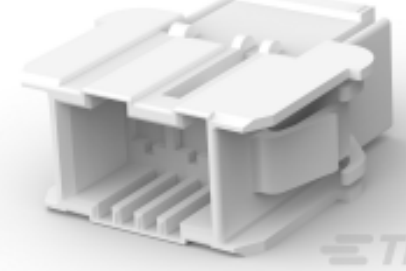
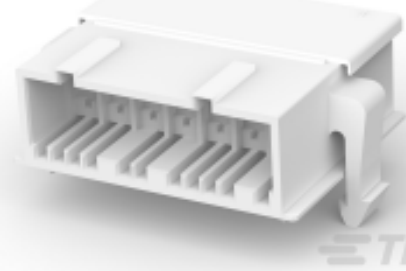
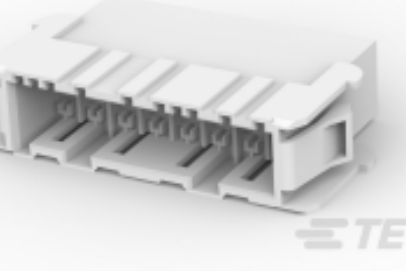
EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

 TE Part # 5-1241967-7 7POS. FASTIN-FASTON* TAB HSG, RAST5	 TE Part # 284985-1 7 POS. FASTIN-FASTON CONN. TAB HSG, RAST	 TE Part # 293010-1 5 POS. FASTIN-FASTON CONN. TAB HOUSING R	 TE Part # 928309-7 7P FF FLACHST GEH
 TE Part # 293034-1 7 POSITION FASTIN FASTON TAB HOUSING (PA	 TE Part # 927742-7 7P FF FLACHSTGH6,3	 TE Part # 1241857-5 5 POS FASTIN/ON HOUSING PANEL MOUNT	 TE Part # 284986-1 8 POS. FASTIN-FASTON CONN. TAB HSG, RAST
 TE Part # 293039-2 7 POS. F.F. TAB HSG MOTOR MOUNT WATER-PR	 TE Part # 293008-3 3 POS. FASTIN-FASTON CONN. TAB HOUSING R	 TE Part # 2-293015-1 7 POS. FASTIN FASTON TAB HSG.	 TE Part # 293015-1 7 POS. FASTIN FASTON TAB HSG.
 TE Part # 1241967-8 FASTIN FASTON TAB HOUSING 8P	 TE Part # 293043-1 8POS. FASTIN-FASTON, TAB HOUSING RAST5		

Also in the Series | RAST 5 IDC Connectors



Connector Contacts(12)



Power Contacts(3)



Rectangular Connector Housings(1)



Rectangular Power Connectors(481)



Standard Edge Connectors(31)



Wire-to-Board Connector Assemblies & Housings(197)

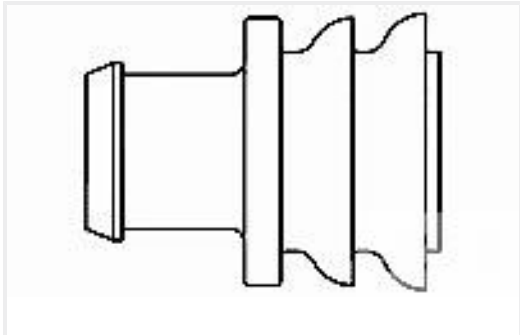
Customers Also Bought



TE Part #114017-ZZ
SEALING PLUG, SIZE 12/16, WHT



TE Part #CAT-AM71-CH8172
AMP SUPERSEAL 1.5MM, CONNECTOR HOUSING



TE Part #281934-2
SINGLE WIRE SEAL



TE Part #CAT-D48-ST273
DEUTSCH Solid Contacts



TE Part #DT04-2P
REC, 2P, GRY, N



TE Part #DT06-2S
PLG, 2P, GRY, N



TE Part #CAT-D487-W416
Wedgelocks: DEUTSCH DT

Documents

Product Drawings

7 POS. FASTIN-FASTON+ TAB HOUSING RAST 5

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_293267-1_A_c-293267-1-a.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_293267-1_A_c-293267-1-a.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_293267-1_A_c-293267-1-a.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[RAST Connector System Catalog](#)

English

Product Specifications

[Product Specification](#)

English

Agency Approvals

[UL Report](#)

English