


FEATURES

- **Non-Releasable Design:** Ensures a secure and permanent fastening solution
- **High Tensile Strength of 22 kg:** Provides robust support for heavy-duty applications
- **UL 94 V-0 Fire Behaviour:** Offers excellent flame retardancy for enhanced safety
- **RoHS Compliant:** Meets environmental and safety standards
- **Nylon Material:** Durable and resistant to wear and tear
- **Maximum Bundle Diameter of 105 mm:** Accommodates larger cable bundles
- **Operating Temperature up to 85 °C:** Suitable for a wide range of environments

RS PRO Nylon Cable Tie, 368 mm Non-Releasable

RS Stock No: 656-039

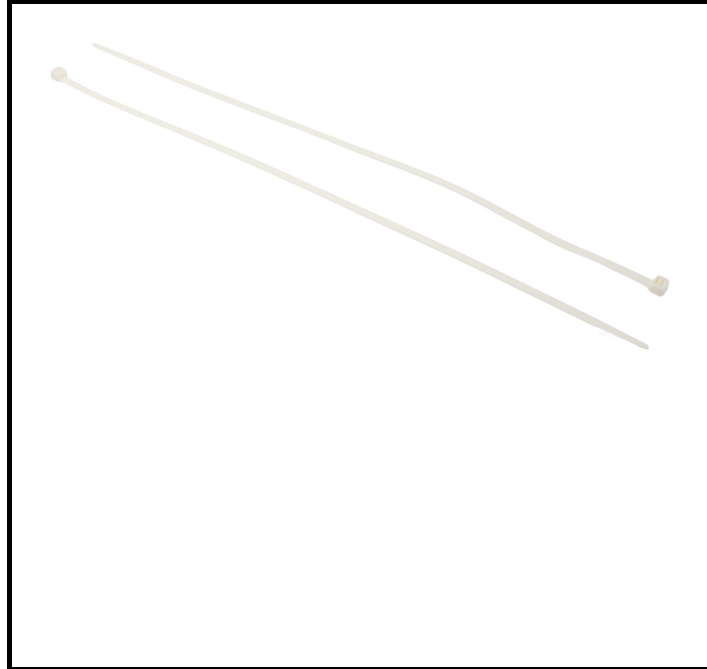

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

These RS PRO nylon cable ties are designed for secure and reliable bundling of cables and wires. With a length of 368 mm, they are ideal for managing larger bundles, ensuring a neat and organised setup. The non-releasable design provides a permanent fastening solution, making them suitable for applications where security is paramount.

General Specifications

Colour	White
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	22 kg

Protection Category

Fire Behaviour	UL 94 V-0
UV Resistant	No

Mechanical Specifications

Length	368 mm
Material	Nylon
Maximum Bundle Diameter	105 mm
Width	4.8 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

Approvals

Standards/Approvals	RoHS, UL94V-0
---------------------	---------------

