


Product Name // M12 Series X Code TPU Flex Body
Overmould Cable Connector 8 Contact Socket Pre-Wired
With 2M PU Jacket Cable

 [View Product Page](#)

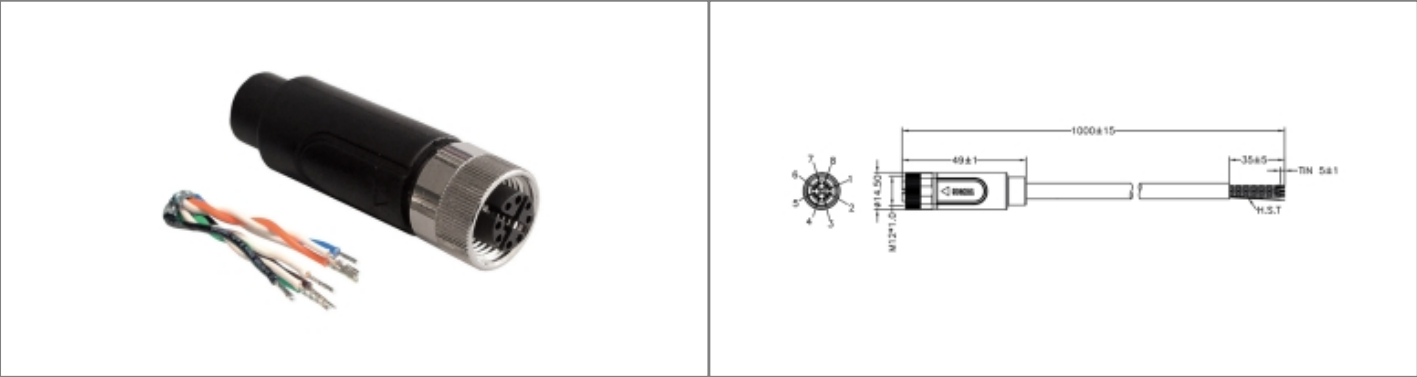

// Product Description:

- ⬢ M12 Series Overmould Flex Body Connectors
 - ⬢ Water and dustproof to IP67 when mated with compatible connector
 - ⬢ Pin or Socket
 - ⬢ 3, 4, 5, 8, 12 Contact (3,12 Contact are A Code, 4 Contact are choice of A Code or D Code, 5 Contact are choice of A Code or B Code, 8 Contact are choice of A Code or X Code)
- ⬢ PCB Terminals
 - ⬢ Choice of mounting nut sizes, depending on part code
 - ⬢ Choice of Sealing Caps available separately to maintain IP rating of unmated connectors
 - ⬢ Mate with M12 Series Inline Body and Flex Body Connectors, depending on part code

// General Information:

Product Display Title:	M12 Series Overmould Flex Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M12 X Coding Series
Body Material:	TPU
Cable Length:	2m
Contact Type:	Socket Contact
Coupling Type:	M12
Current Max:	0.5A
Function:	Flex Connector Single Ended Cable
Ip Rating:	IP67
Max Operating Temperature:	+85°C
Min Operating Temperature:	-25°C
Number Of Contacts:	8 Contacts
Sheath Material:	PUR
Voltage Max:	48V

// Product PDF Links

 [M-Series Technical Product Data](#)

// Product 3D CAD Model Links

 [PXPTPU12FBF08XCL020PU3D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)