


Plastic tubing PAN-4X0,75-SI-500

Part number: 553888

FESTO

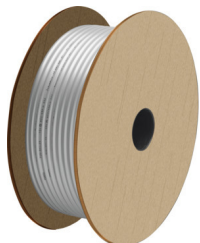

 General operating condition

Data sheet

Feature	Value
Outside diameter	4 mm
Flow-relevant bending radius	18 mm
Inside diameter	2.9 mm
Min. bending radius	12 mm
Tubing characteristics	Suitable for energy chains
Temperature-dependent operating pressure	-0.095 MPa ... 1.5 MPa
Temperature-dependent operating pressure	-0.95 bar ... 15 bar
Temperature-dependent operating pressure	-13.775 psi ... 217.5 psi
Approval	German Technical Control Board (TÜV)
Maritime classification	See certificate
Certificate issuing authority	B 013277 0506 00
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-30 °C ... 80 °C
Product weight according to length	0.006 kg/m
Pneumatic connection	For push-in connector O.D. 4 mm For barbed fitting I.D. 3 mm with union nut For barbed fitting I.D. 3 mm
Colour	Silver
Shore hardness	D 55 +/-3
Note on materials	RoHS-compliant
Material tubing	TPE-A