




**125-70-1**  
**1/2" Pear Type Reversible Ratchets**

**PRODUCT DETAILS**

- 72 teeth/5° action angle
- Quick-release function
- Quick, easy direction change lever on wrench head
- Slim head for narrow places
- Rounded shapes and highly polished surfaces with no sharp points
- Comfortable non-slip two-component handle with hanging hole for easy storage
- Made of high-performance alloy steel, precision forged and heat treated for optimum durability
- Retail packed on an anti-theft plastic card
- Standards: ISO 3315/1174-2, DIN 3122/3120

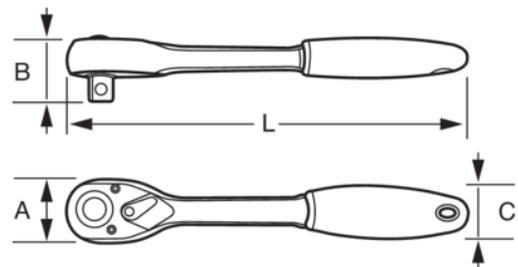

**PRODUCT ATTRIBUTES**

Product				<b>A</b>	<b>B</b>	<b>C</b>	<b>L</b>	
<b>125-70-1</b>	1/2 in	5 °	72	42 mm	41 mm	36 mm	262 mm	591 g