

PLIERS

FATMAX® COMPOUND ACTION PLIERS – LONG NOSE

STANLEY
FATMAX.

- Ideal for maximising grip and manoeuvring small objects in confined spaces
- 70% more gripping power



STANLEY	Description	
FMHT0-70812	FatMax® Compound Action Pliers- Long Nose*	Carded

*Available from March 2014

NEW

FATMAX® COMPOUND ACTION PLIERS – END CUTTERS

STANLEY
FATMAX.

- Ideal for very close cropping of wire, nails and fasteners
- 70% more cutting power



STANLEY	Description	
FMHT0-71851	FatMax® Compound Action Pliers- End Cutters*	Carded

*Available from March 2014

NEW

FATMAX® COMPOUND ACTION PLIERS – 3 PACK

STANLEY
FATMAX.

- Pack contains: Long Nose, Combination and Diagonal pliers



STANLEY	Description	
FMHT0-72415	FatMax® Compound Action Pliers- 3 pack *	Carded

*Available from March 2014

NEW

THE PRO'S ADVICE




THE RIGHT PLIERS FOR THE JOB

COMPOUND ACTION PLIERS

Compound action pliers use technology similar to that found in bolt croppers and aviation snips. A double pivot gives a massive mechanical advantage meaning user input is multiplied – giving more cutting and gripping force for the same input. These are ideal for cutting thicker wires and cables and can also benefit users with an impaired gripping action.

WIRE CUTTING

Pliers do not cut by shearing, as scissors do, they cut wire by partially cutting and finally 'separating' the wire. The cutting edges should be precision ground, but the actual edge should be filed flat to separate rather than cut.

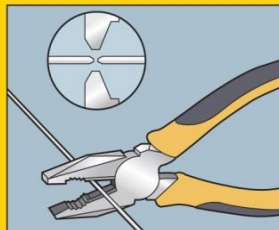

COMBINATION PLIERS

For gripping and cutting these are indispensable and should be found in every tool box. The 180mm long model is probably the most versatile.

DIAGONAL AND END CUTTERS

For wire cutting only. The FatMax models are made to demanding DIN/ASO/ANSI and are capable of cutting hard steel wire. The end cutter can exert a higher leverage than the diagonal and is easier if you have a lot of repetition cutting of hard wire.

STRAIGHT AND CRANKED LONG NOSE PLIERS

The long gripping nose is rounded and very useful for twisting electrical wire to make good contacts. Long nose pliers also have a cutting edge suitable for copper and fine gauge soft steel. The 160mm model is compact and easy to use.

VDE RANGE

Offers additional safety in electrical applications with 1000v rated handles, safe live line working, with handles tested up to 10,000v.

WATER PUMP PLIERS

Featuring adjustable jaw capacities, they are ideal for plumbing when it comes to working on large size flange nuts. The specially fluted jaw profile also helps grip piping securely.

SLIP JOINT PLIERS

A general purpose gripping tool with smaller adjustable jaw capacities than Water Pump Pliers, but with the added feature of a wire shear built into the jaw. A very useful and adaptable tool for any toolbox.

'MOLE' LOCKING PLIERS

Available with straight and curved jaws suitable for locking onto flat surfaces such as nuts and bolts or metal bars.

**SEE ALL THE PRO'S ADVICE AT
STANLEYTOOLS.CO.UK**