


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed r/min		* SKF Explorer bearir
mm			kN		r/min		-
34,925	65,088	18,034	47,3	57	7500	11000	LM 48548/510/Q

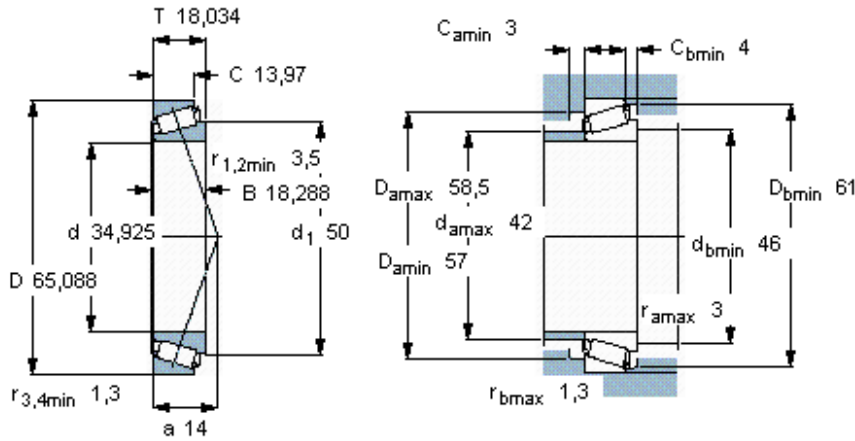

Calculation factors

e 0,37
Y 1,6
Y₀ 0,9