

PVC plug mini

SCHUKO / French/Belgian standard

1418000






General information

Item number	1418000
Model	PVC plug mini
Colour	black

Electrical parameters

Amperage	16A
Voltage	250V
Poles	2P + PE

Standards/Directives

According to	DIN VDE 0620 / NF C61-314 / NBN C61-112
Standard	SCHUKO / French/Belgian standard
Certification marks	  

Operating conditions


Storage temperature	-15°C to +60°C
Operating temperature	-15°C to +35°C
Relative humidity	5 to 95%, no condensation
Degree of protection	IP20

Materials

Contact Carrier	PA
Housing	PVC

Connecting cable


Cross section	3x0,75mm ² -3x1,5mm ²
Cable diameter, dimension a	6-10,4mm
Insulation strip length sheath, dimension b	33-35mm
Trim L/N, dimension c	8mm
Insulation strip length cores, dimension d	8-10mm

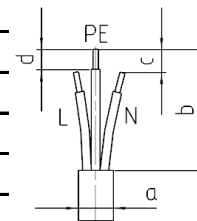

Connection screws

Max. torque for screws L-N/PE	0,5 Nm/0,8Nm
Screw drive L-N/PE	Combined slot/PZ1/PZ2
Max. torque for screws housing	0,5 Nm
Screw drive housing	Combined slot/PZ1
Max. torque for screws strain relief	0,5 Nm
Screw drive strain relief	Combined slot/PZ1

Subject to modifications

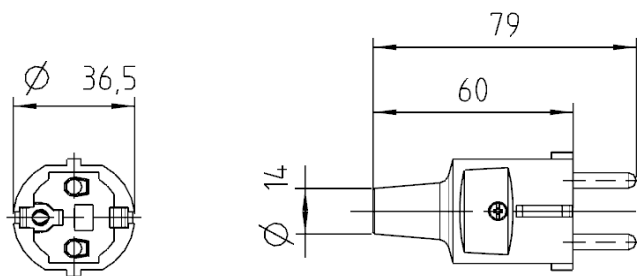

If the application requires extended specifications, we recommend to test the application under real or simulated conditions. Parameters like duration, quantity and temperature will effect the result significantly