


Straight 4mm Banana Plug to Right-Angle 4mm Banana Plug Lead

Applications : to connect to safety 4 mm banana jacks, sockets, and binding posts. General purpose electric testing, controlling, and measuring.



IP2X touchproof protection on the 4 mm banana connections to prevent accidental contact.

The connections do not need any insulating cap that can be lost because they include a permanent insulating gray tip which offers IP2X touchproof protection.

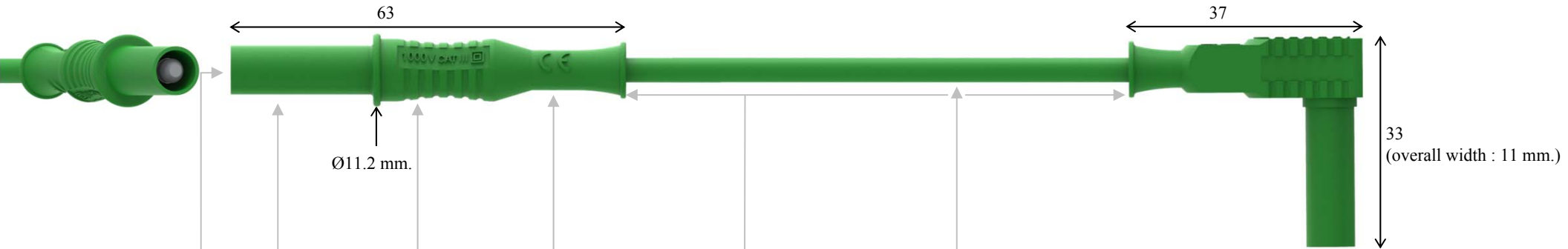

Insulating gray tips on the 4 mm banana male connections to prevent accidental contact.

The design and the material of the lantern contact springs meet the need of low resistance and reliability.

Voltage Markings.

European Union marking.

Current marking.

The wire attachments comply with heavy duty.

Double jacket wire to offer a wire wear indicator. PVC wire for low cost. Cross section area 0.75 mm² for current 12 A. Usual lengths 25 cm, 50 cm, 100 cm and 200 cm (visible length of the wire, not the overall length of the lead).

The 4 mm banana male connections comply with the 4 mm banana sockets of the worldwide most famous manufacturers and meet the requirements of interchangeability dimensions of the standard NF C 93-440:1986.

Straight 4mm Banana Plug to Right-Angle 4mm Banana Plug Lead



Specification

Electrical protection	1000 V CAT II / 1000 V CAT III / 600 V CAT IV, reinforced insulation, pollution degree 1 or 2, up to 36 A
Operating Temperature Range	-20 °C...+80 °C

RND Part Nr.	Colour	Length
RND 350-00091	Black	500 mm
RND 350-00092	Red	500 mm
RND 350-00093	Blue	500 mm
RND 350-00094	Black	1 m
RND 350-00095	Red	1 m
RND 350-00096	Blue	1 m
RND 350-00097	Black	2 m
RND 350-00098	Red	2 m
RND 350-00099	Blue	2 m