




## LED FIL XTRA A60 E27 7.2W (100W) 1521lm 830 Clear Class A

Article number: 146967

BAI LED Filament XTRA GLS A60 E27 7.2W (100W) 1521lm 3000K Clear Class A 230V-240V 320° 60x105mm 35.000h LED-lamp

For years, LED filament bulbs have been the sustainable alternative to incandescent, halogen, and CFL lamps. The Bailey Led Filament Xtra takes it even further. It is so energy-efficient that it proudly carries the rare energy label A, introduced under the stricter 2021 regulations. With an impressive lifespan of 35,000 hours, a strong light output of 1521 lumens, and ultra-low energy use of just 7.2 watts, this bulb matches the brightness of a traditional 100W incandescent. Its warm 3000K color temperature offers cozy, eye-friendly lighting. The standard E27 base fits seamlessly into almost all Bailey decorative lamp holders and pendant sets.

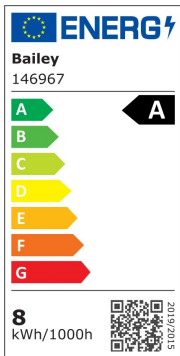

### General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL XTRA A60 E27 7.2W (100W) 1521lm 830 Clear Class A
Brand	Bailey
Productseries	LED Filament GLS
Producttype	A60 XTRA

## ETIM specifications

Socket	E27
Luminous flux [lm]	1521 - 1521
Nominal voltage [V]	220 - 240
Lamp power [W]	7.2 - 7.2
Colour temperature [K]	3000 - 3000
Diameter [mm]	60
Length [mm]	105
Dimmable	No
Lamp shape	Pear-shape
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Lamp designation	A-type
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	1521
Power factor	0.5
Lamp efficacy [lm/W]	211
Nominal current [mA]	55 - 55
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	35000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	8
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

---

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	A
With twilight switch	No
Material of light bulb	Glass