




ENGLISH

Datasheet

Stock No: 290-8748

RS Pro 2000mm x 25mm x 5mm 316 Stainless Steel Rectangular Bar

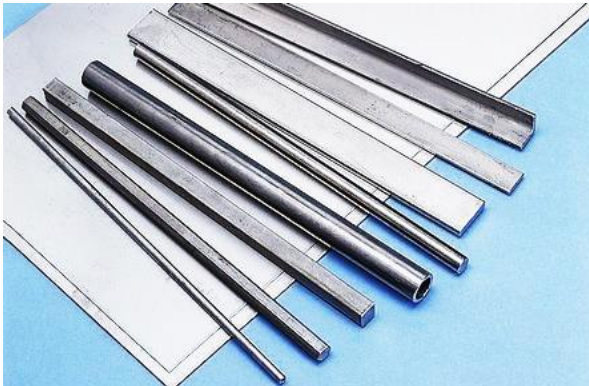

Product Details

316 Stainless Steel Bar and Angle

Properties C = 0.08 maximum, Ni 12.0, Cr17, Mo2.25

Bar to EN10088-3/ EN10051

Related specifications AS2837-1986-316, AISI TYPE 316, ASTM A276-316

Used particularly in the chemical and allied industries, especially in conditions of pit-type corrosion

Bar, Angle & Key Steel - Grade 316 (A4)

Austenitic stainless steels which are highly resistant to corrosion due to their Molybdenum content. They are non-magnetic and suitable for applications such as photographic, food, chemical and marine equipment.

Specifications:

Material	316 Stainless Steel
Form	Rectangular Bar
Length	2000mm
Width	25mm
Height	5mm