


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

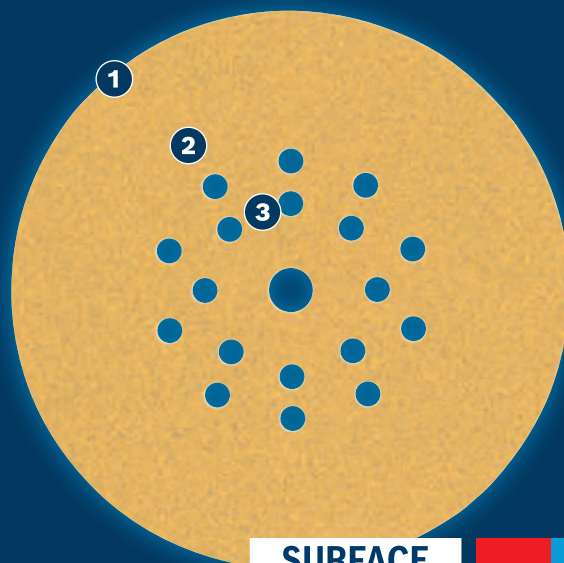

SURFACE
STRUCTURE

UP TO
2x*



* vs. Bosch C420




Video



BOSCH

EXPERT C470 SANDING DISCS

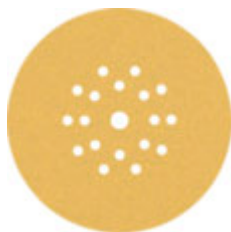

- Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- EXPERT Abrasives - the very best for all trades
- Up to 2x faster than Bosch C420 Sandpaper
- Just stick it on with hook and loop



PRODUCT PROPERTIES				ORDERING INFORMATION				
Disc diameter mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number	
225	40	no holes	C0a	1	25	573 526	2 608 901 019	
225	60	19 holes	C0a	1	25	573 489	2 608 901 015	
225	60	no holes	C0a	1	25	573 533	2 608 901 020	
225	80	no holes	C0a	1	25	573 540	2 608 901 021	
225	120	no holes	C0a	1	25	573 557	2 608 901 022	
225	180	no holes	C0a	1	25	573 564	2 608 901 023	
225	40	19 holes	C1a	5	3	636 214	2 608 901 671	
225	80	19 holes	C1a	5	3	636 221	2 608 901 672	
225	120	19 holes	C1a	5	5	636 238	2 608 901 673	
225	180	19 holes	C1a	5	3	636 245	2 608 901 674	
225	1x40	19 holes	C1a	6	3	638 256	2 608 901 677	
	1x80							
	2x120							
	2x120							
225	40	19 holes	C0a	25	1	544 847	2 608 901 146	
225	60	19 holes	C0a	25	1	544 854	2 608 901 147	
225	80	19 holes	C0a	25	1	544 861	2 608 901 148	
225	100	19 holes	C0a	25	1	544 878	2 608 901 149	
225	120	19 holes	C0a	25	1	544 885	2 608 901 150	
225	150	19 holes	C0a	25	1	544 892	2 608 901 151	
225	180	19 holes	C0a	25	1	544 908	2 608 901 152	
225	220	19 holes	C0a	25	1	544 915	2 608 901 153	



BOSCH