




SIVACON, side panel / rear panel, Closed, IP40, H: 1800 mm, W: 600 mm, RAL 7035

Model		
product brand name	SIVACON	
product designation	Side panel/rear panel	
design of the product	Closed	
design of the surface	Powder-coated	
design of the product EMC version	No	
Protection class		
protection class IP	IP40	
Appearance		
RAL color number	RAL 7035	
color	light grey	
Product details		
product component		
• cable entry	No	
• lock	No	
Mechanical Design		
height	1 800 mm	
width	600 mm	
depth	600 mm	
material	steel	
Approvals Certificates		
General Product Approval	Test Certificates	other
		
	Special Test Certificate	Confirmation Miscellaneous
other	Environment	
Miscellaneous		Environmental Confirmations

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	

Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1860-2UW60-1C>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1860-2UW60-1C>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1860-2UW60-1C
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

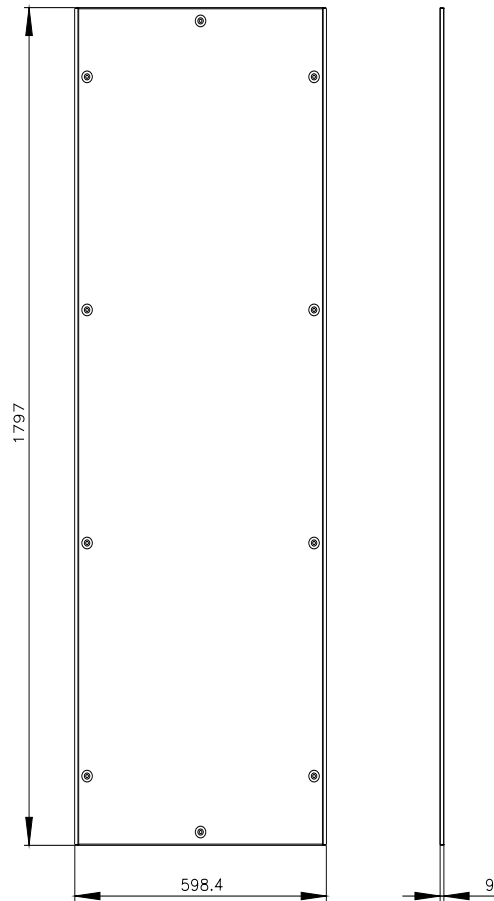

last modified: 5/24/2025

